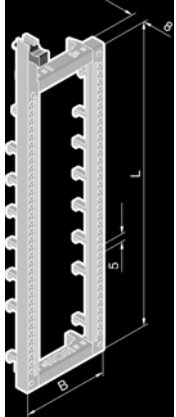


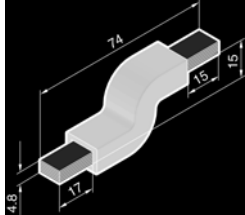
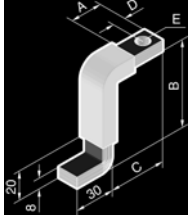
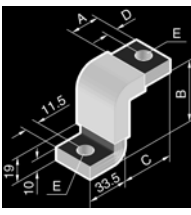
Kannatinkehys

Päälueetelo 33, sivu 320

OM-adapterille ja OM-kannattimelle				
Leveys (B) mm	45	45	55	55
Pituus (L) mm	170	237	170	237
Til.nro SV	9341.800	9341.820	9341.830	9341.850

Liitäntäkulma

Päälueetelo 33, sivu 322

CB-laiteadapterille									
Mitat ¹⁾ mm	6 x 9 x 0,8	10 x 15,5 x 0,8				10 x 32 x 1			
A mm	-	26	19	23	19	26	29	28	
B mm	-	65	66	71	67	51	57	62	
C mm	-	43	36	40	36	62	46	38	
D mm	-	9	10	9	7	9	12	14	
E mm	-	Ø 11	Ø 11	Ø 11	Ø 8	Ø 12	Ø 12	Ø 12	
Til.nro SV	9342.570	9342.660	9342.670	9342.680	9342.690	9342.770	9342.780	9342.790	

¹⁾ Lamellien määrä x lamellileveys x lamellipaksuus.