
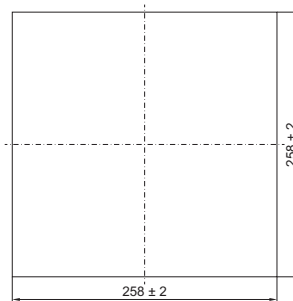


### Dachlüfter, Dachentlüftung

SK 3138.000, SK 3139.100, SK 3139.110, SK 3140.100, SK 3140.110, SK 3140.140, SK 3140.500, SK 3140.510

Montageausschnitt

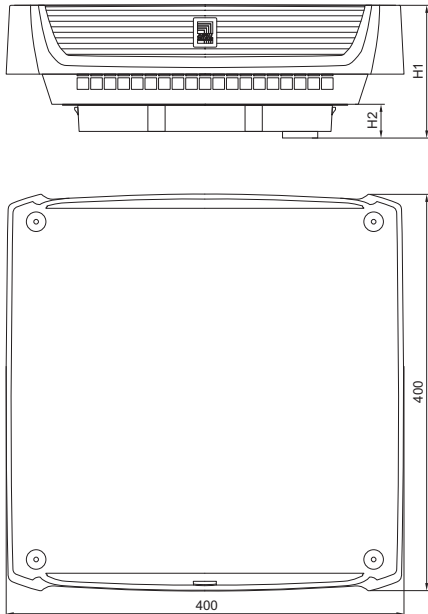


Best.-Nr. SK	H1 mm	H2 mm
3138.000	133	27,5
3139.100	133	34,6
3139.110	133	34,6
3140.100	133	34,6
3140.110	133	34,6
3140.140	133	34,6
3140.500	133	34,6
3140.510	133	34,6

### Einschublüfter

für 482,6 mm (19")


Einschublüfter  
SK 3340.230, SK 3341.115, SK 3341.230,  
SK 3342.024, SK 3342.230, SK 3342.500

Montage in die 482,6 mm (19")-Ebene

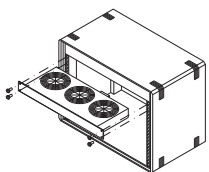


Einschublüfter Vario  
SK 3350.230, SK 3351.230,  
SK 3352.230, SK 3352.500

Montage in Baugruppenträger 84 TE

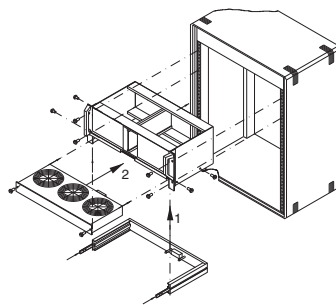



Einschublüfter Vario  
SK 3350.230, SK 3351.230,  
SK 3352.230, SK 3352.500

Montage in die 482,6 mm (19")-Ebene

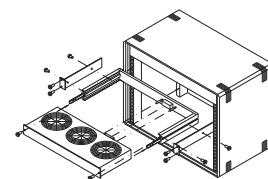

### Drucklüfter

3144.000

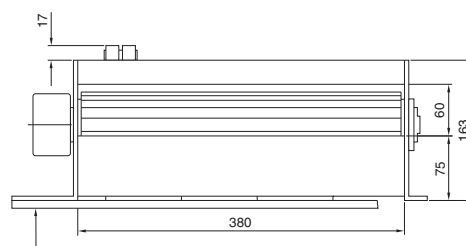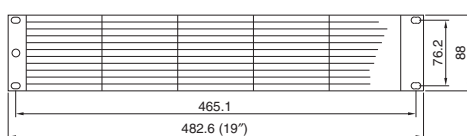

Frontgitter