

RiLine accessories: for NH fuse-switch disconnectors/NH slimline fuse-switch disconnectors

Box terminals


for NH disconnectors, size 1 to 3 with screw terminal

| For NH disconnectors | Clamping area for laminated copper bars W x H mm | Connection | | Tightening torque Nm | Model No. SV |
|----------------------|-----------------------------------------------------|------------------------------------|--------------------------------------------|-------------------------|-----------------|
| | | Round conductor mm ² | Sector-shaped conductor mm ² | | |
| Size 1 | 20 x 14 | 35 – 150 | 50 – 150 | 12 | 9344.610 |
| Size 2/3 | 32 x 20 | 95 – 300 | 120 – 300 | 20 | 9344.620 |

Connection space cover

for NH disconnectors

| For NH disconnectors | Width (B) mm | Height (H) mm | Depth (T) mm | Model No. SV |
|----------------------|-----------------|------------------|-----------------|-----------------|
| Size 00 | 106 | 46 | 37 | 9344.520 |
| Size 1 | 184 | 70 | 42 | 9344.530 |
| Size 2 | 210 | 70 | 42 | 9344.540 |
| Size 3 | 250 | 70 | 42 | 9344.550 |

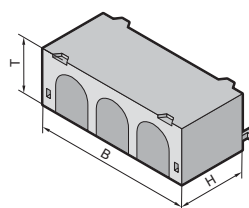

Clamp-type terminal connection

for NH slimline fuse-switch disconnectors, size 00 with screw terminal

| Connection of round conductors mm ² | Tightening torque Nm | Model No. SV |
|---------------------------------------------------|-------------------------|-----------------|
| 1.5 – 95 | 4 | 3592.010 |