


Verteilerrahmen

TE 7000 open Handbuch 33, Seite 110


DK 7000.940

Vorderansicht

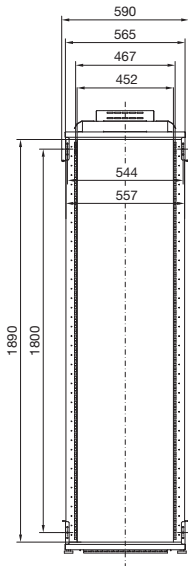


DK 7000.944


Vorderansicht

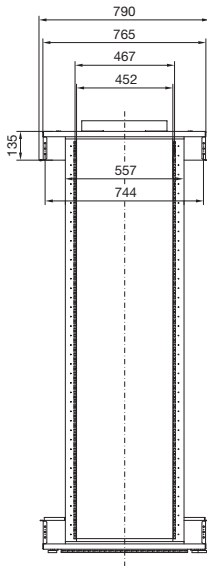


Seitenansicht

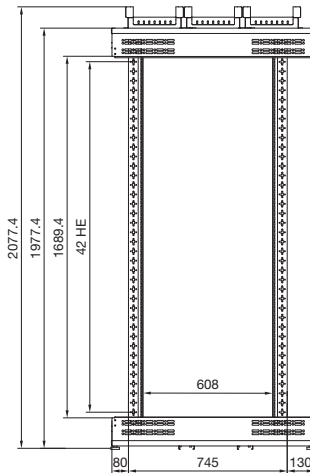

Draufsicht

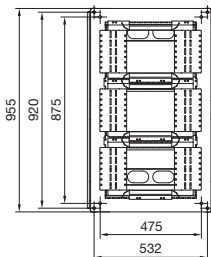


Draufsicht

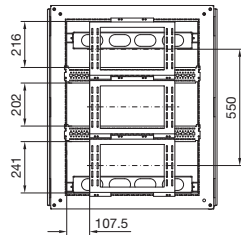


Data Rack Handbuch 33, Seite 111

Vorderansicht

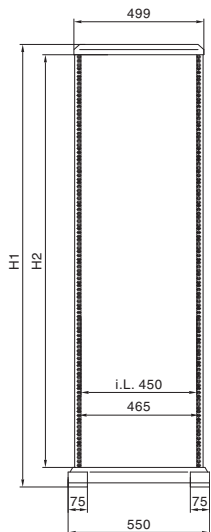

Seitenansicht

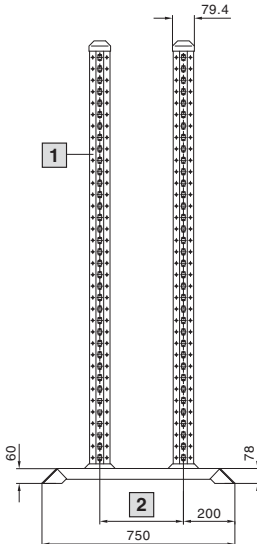

- 1** Zweite Befestigungsebene
DK 7296.000/31 HE
DK 7297.000/36 HE
DK 7298.000/40 HE
DK 7299.000/45 HE
- 2** Im 50 mm Raster
(min. 150 – max. 350)

Best.-Nr. DK	HE	Höhenmaße mm	
		H1	H2
7391.000	31	1500	i. L. 1382
7396.000	36	1722	i. L. 1604
7400.000	40	1900	i. L. 1782
7445.000	45	2122	i. L. 2004