




Systemausbau

Wände


Trennschalterhaube

für VX, Stahlblech und Edelstahl


VX 8951.000, VX 8951.010, VX 8951.020, VX 8951.030
 VX 8952.000, VX 8952.010, VX 8952.020, VX 8952.030

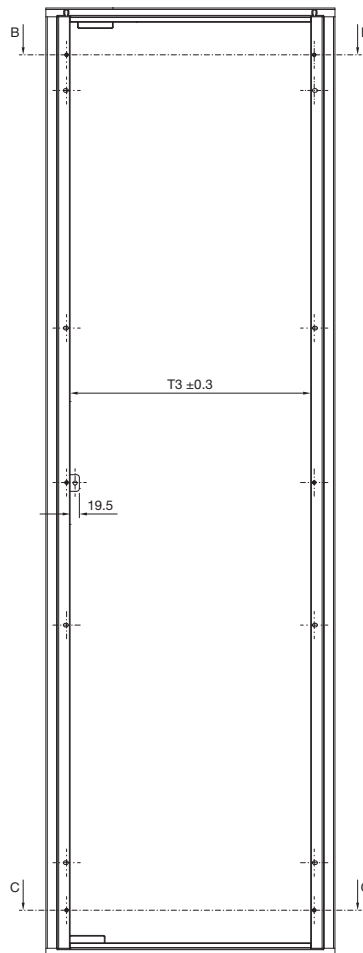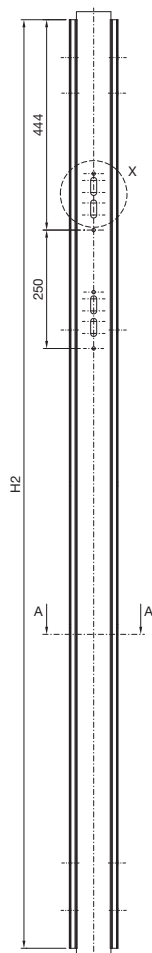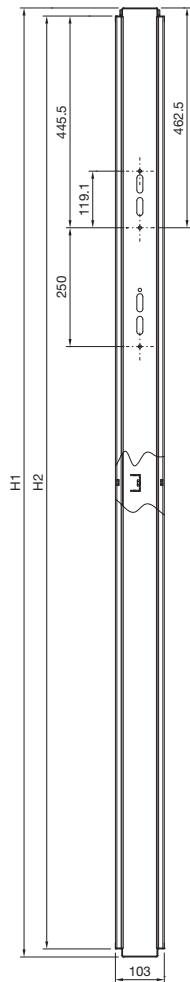


Einzelheit X

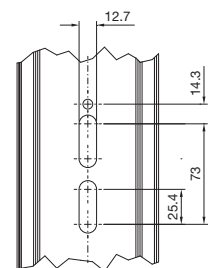


Schnitt A – A

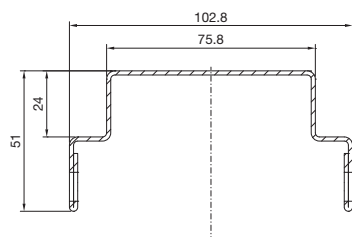

Schnitt B – B

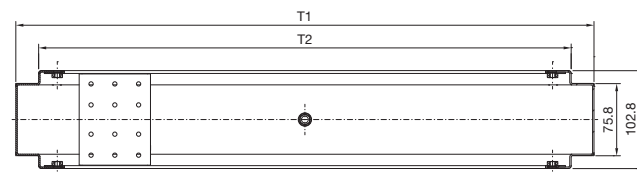

Schnitt C – C

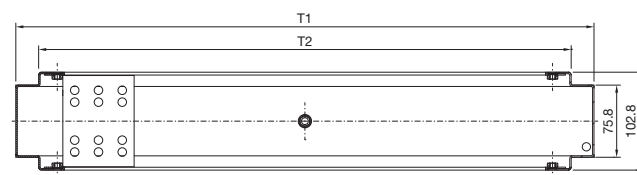

Best.-Nr. VX		Für Schränke		Höhenmaße mm		Tiefenmaße mm		
Stahlblech	Edelstahl	Höhe mm	Tiefe mm	H1	H2	T1	T2	T3
8951.000	8952.000	2000	500	1997	1963	508,2	460,2	406,2
8951.010	8952.010	2000	600	1997	1963	608,2	560,2	506,2
8951.020	8952.020	1800	400	1797	1763	408,2	360,2	306,2
8951.030	8952.030	1800	500	1797	1763	508,2	460,2	406,2