


Rittal – The System.

Faster – better – everywhere.

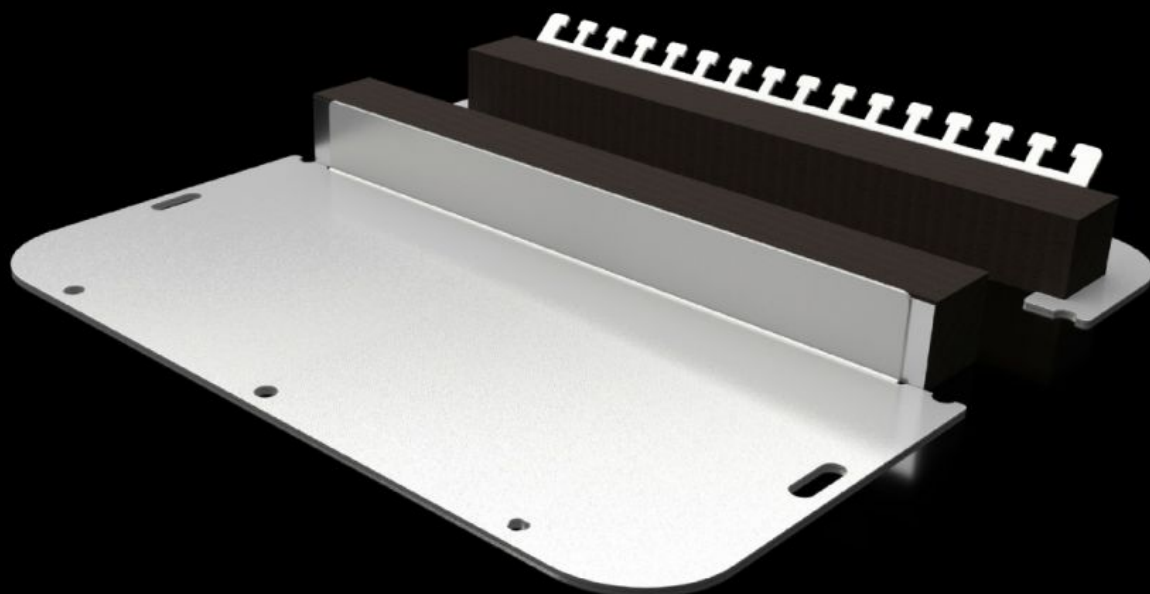

SZ 2565.450

Two-part gland plate with foam rubber cable clamp strip

Состояние: 27.09.2024 (Источник: rittal.com/by-ru)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2565.450 - Two-part gland plate with foam rubber cable clamp strip для AX

The divided gland plate supports simple mounting on the enclosure and offers a range of different installation options. For simple insertion of cables with and without connectors into the enclosure. Special drilled holes in the gland plate ensure automatic potential equalisation during screw-fastening. Bolts, clips and earthing cables are no longer required.

Функции

Арт. №	SZ 2565.450
Исполнение	two-piece
Материал	Листовая сталь
Цвет	RAL 7035
Комплект поставки	Вкл. крепежный материал
Указание	Соответствие размеров фланш-панелей можно найти у соответствующих корпусов. When installing in enclosure width >760 mm, 2 packs are required
Размер	Ширина: 301 мм Глубина: 221 мм
Подходит для	Тип корпуса: AX
Подходит для арт. №	1037.000 1055.000 1073.000 1180.000 1280.000 1338.000 1181.000 1281.000
Фланш-панель	Размер: 5
Упаковка	1 шт.
Вес	1,02 кг
Вес нетто	0.95

Функции

Gross weight	1.02
PCF/PU (Cradle-to-Gate)	3,9 kg CO2 eq (Cat B)
Note on the PCF class	Category B: PCF value (cradle-to-gate) approximated based on product weight and self-declared
Код ТНВЭД	73269098
EAN	4028177973152
ETIM 8	EC000211
ETIM 7.0	EC000211
ECLASS 8.0	27142421