


Rittal – The System.

Faster – better – everywhere.

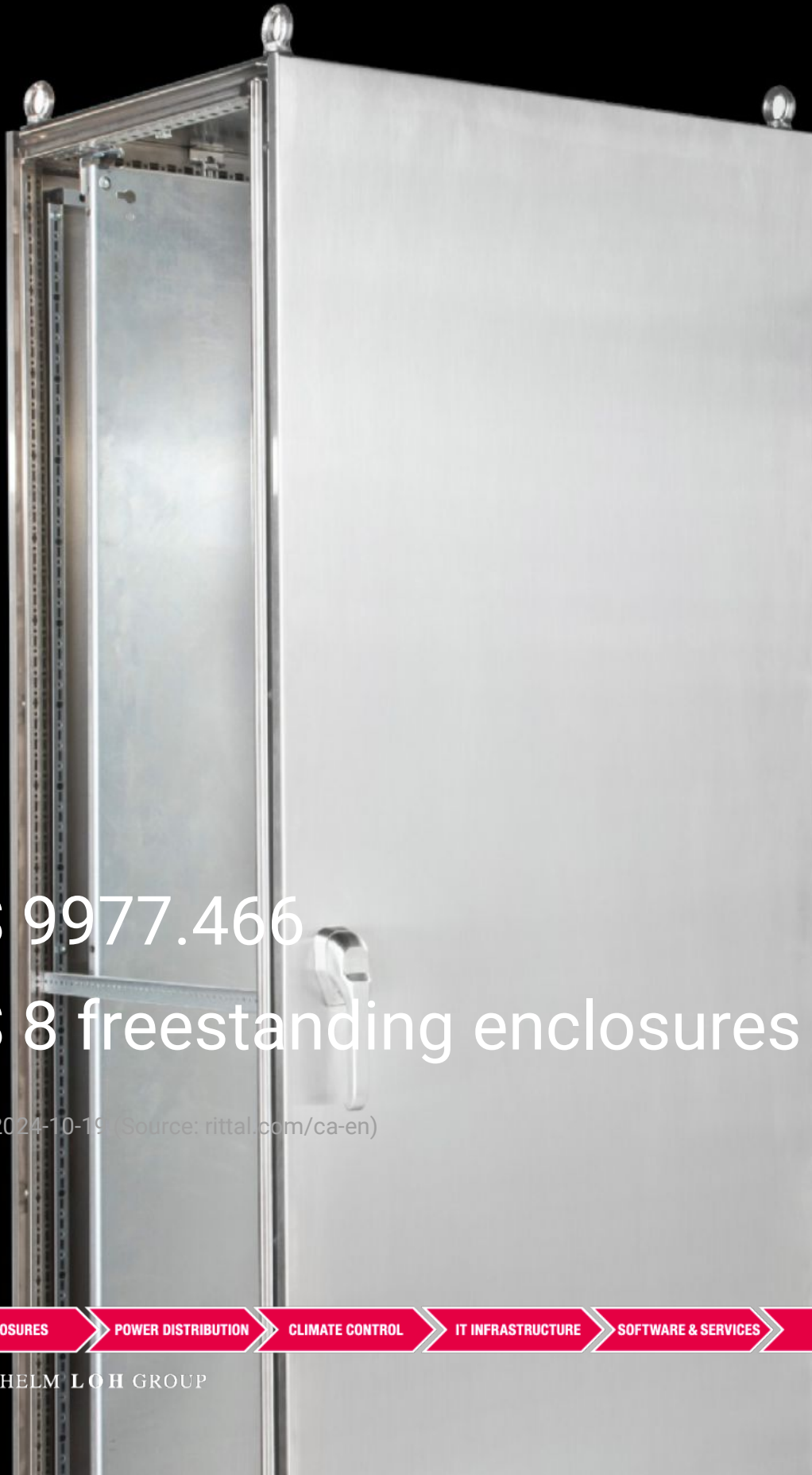

TS 9977.466 TS 8 freestanding enclosures

State: 2024-10-19 | Source: rittal.com/ca-en

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TS 9977.466 - TS 8 freestanding enclosures Stainless steel

Baying systems TS 8 with mounting plate. Protection category IP 66 (UL Type 4X). Manufactured in stainless steel 1.4404 (AISI 316L) Enclosure widths include 600 and 800 mm.



Features

Model No.	TS 9977.466
Material	Enclosure frame: Stainless steel 1.4404 (AISI 316L), 1.5 mm Roof: Stainless steel 1.4404 (AISI 316L), 1.5 mm, exterior brushed Door: Stainless steel 1.4404 (AISI 316L), 2.0 mm, exterior brushed Rear panel: Stainless steel 1.4404 (AISI 316L), 1.5 mm, exterior brushed Gland plate: Stainless steel 1.4404 (AISI 316L), 2.5 mm
Surface finish	Enclosure frame and base plates: Uncoated Door, roof and rear panel: Exterior brushed, grain size 400 Mounting panel: Zinc-plated
Supply includes	Gland plate Padlockable handle

Features

Dimensions	Width: 800 mm Height: 2,000 mm Depth: 800 mm
------------	--

Packaging unit	1 pc(s).
----------------	----------

Weight/packaging unit	137 kg
-----------------------	--------

Net weight	336.995
------------	---------

Gross weight	336.995
--------------	---------

Customs tariff number	7326909099
-----------------------	------------

UPC-Code	88037
----------	-------

Approvals

Approvals	UL + C-UL (listed)
-----------	--------------------