
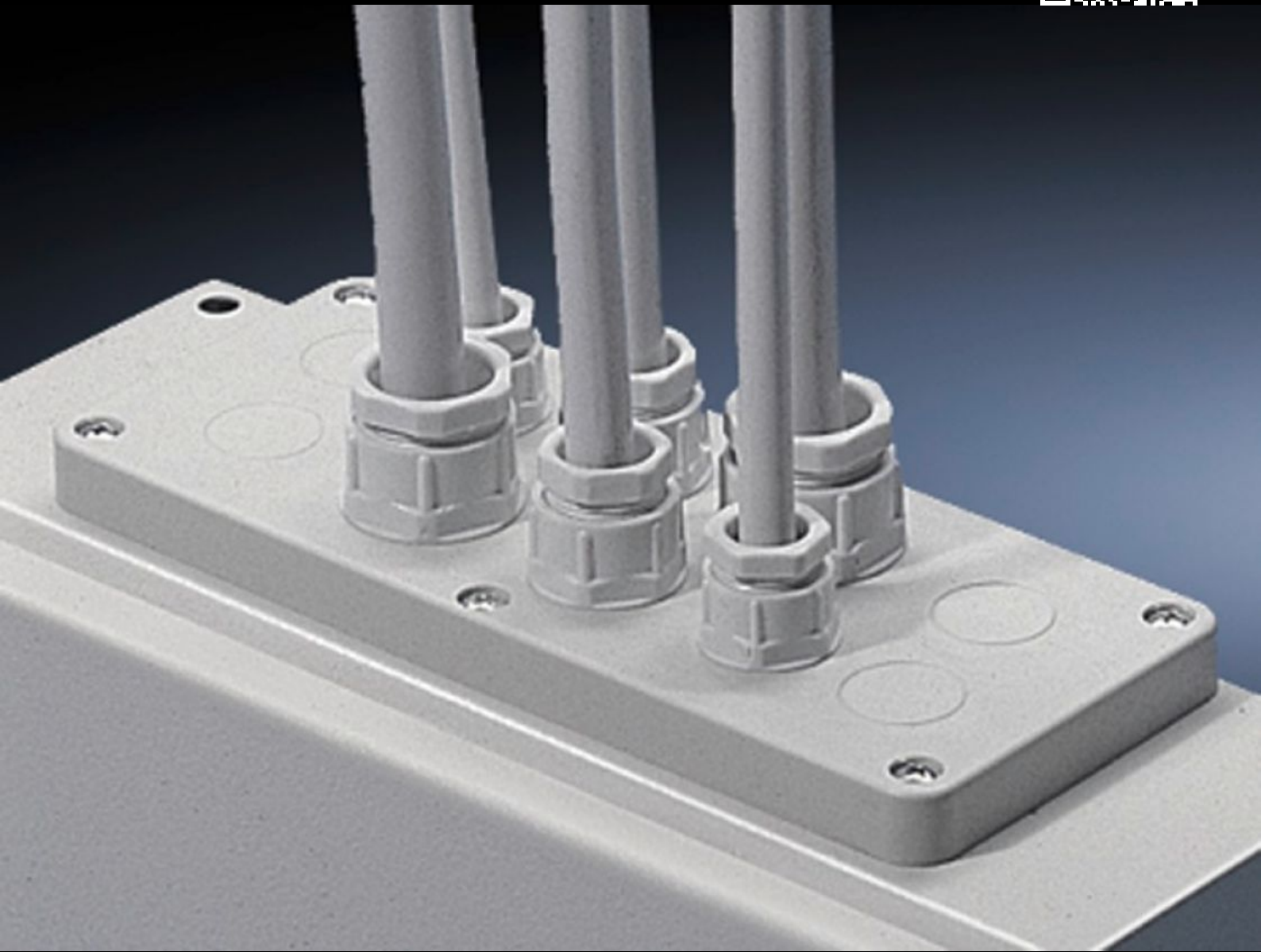


Rittal – The System.

Faster – better – everywhere.

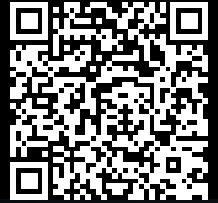

KL 1581.000 Plastic cable gland plates

State: 26/09/2024 (Source: [rittal.com/com-en](https://www.rittal.com/com-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES



FRIEDHELM LOH GROUP

KL 1581.000 - Plastic cable gland plates with PG knockouts

With pre-punched PG holes for cable glands.



Features

Model No.	KL 1581.000
Product description	With pre-punched PG holes for cable glands. Use seal for standard gland plates.
Material	ABS
Colour	RAL 7035
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
No. of metric knockouts	12
Number x PG diameter	12 x 13.5
Dimensions	Width: 220 mm Depth: 90 mm
To fit	Enclosure type: KL
Gland plate	Size: 2
Operating temperature range	-40 °C...70 °C
Protection category to IEC 60 529	IP 55 if installed correctly
Number knockouts	12
Packs of	5 pc(s).

Features

Weight/pack	0.6 kg
Net weight	0.505
Gross weight	0.604
Customs tariff number	73269098
EAN	4028177010888
E-Number Sweden	E3404715
ETIM 8	EC000211
ETIM 7.0	EC000211
ECLASS 8.0	27142421