
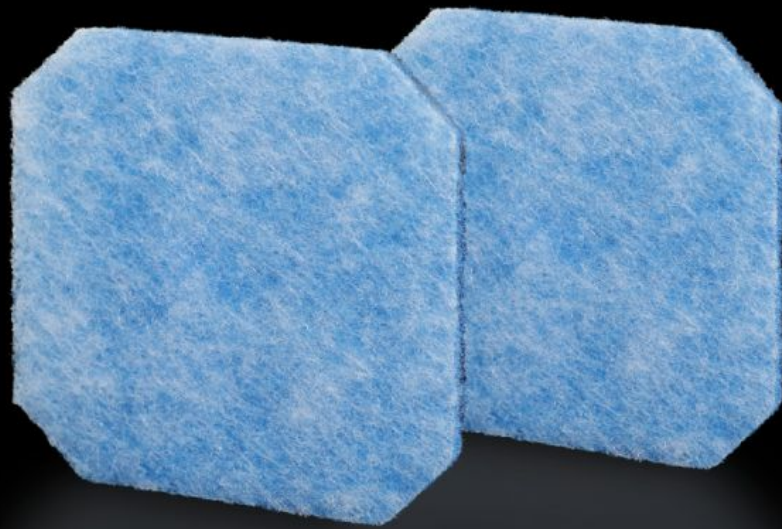


Rittal – The System.

Faster – better – everywhere.

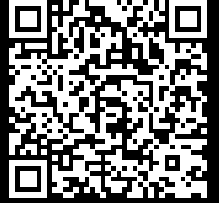

SK 3321.700

Chopped-fibre filter mat

State: 01/02/2025 (Source: rittal.com/com-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SK 3321.700 - Chopped-fibre filter mat

Spare filter mats for roof-mounted fans, fan-and-filter units or thermoelectric coolers, for effective protection of enclosure components from dirt, dust and water.

Features

Model No.	SK 3321.700
Design	for fan-and-filter units
Product description	Made of chopped-fibre mat with a progressive structure. Temperature-resistant to 100 °C, self-extinguishing category F1 to DIN 53 438. Dust-laden air side: Open structure. Clean-air side: Closed structure. Reliable filtering of virtually all types of dust from a particle size of 10 µm.
Material	Chemical fibres
Note	Performance data, protection category and device approvals are only guaranteed when used in conjunction with original Rittal filter mats.
To fit Model No.	3237.2xx/3237.1xx
Dimensions	Width: 89 mm Height: 89 mm Depth: 10 mm
Filter class	to DIN EN 779: G2 to DIN EN ISO 16890: ISO Coarse 50%
Weight/pack	0.001 kg
Packs of	5 pc(s).
Net weight	0.005
Gross weight	0.007
Customs tariff number	56039390
EAN	4028177184282
E-Number Sweden	E3404732
ETIM 9	EC002513

Features

ETIM 8	EC002513
--------	----------

ECLASS 8.0	27180706
------------	----------

Approvals

Certificates	EAC
--------------	-----