


Rittal – The System.

Faster – better – everywhere.

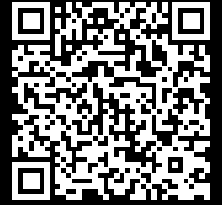

IT 3659.181 Server telescopic slides

State: 03/07/2024 (Source: rittal.com/com-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



IT 3659.181 - Server telescopic slides for IT rack systems and IT racks

Ensure optimum access to the servers, even when built-in. For servers with a maximum width of 430 mm.



Features

Model No.	IT 3659.181
Design	For 470.65 - 599.65 mm distance between levels
Product description	Ensure optimum access to the servers, even when built-in. For servers with a maximum width of 430 mm.
Material	Sheet steel
Load capacity	30 kg
Note	Only in conjunction with L-shaped mounting angles
To fit	Enclosure type: TS TS IT VX VX IT Depth: = 600 mm
Packs of	2 pc(s).
Weight/pack	1.33 kg
Customs tariff number	73269098
EAN	4028177964945
ETIM 7.0	EC002620
ECLASS 8.0	27189261