
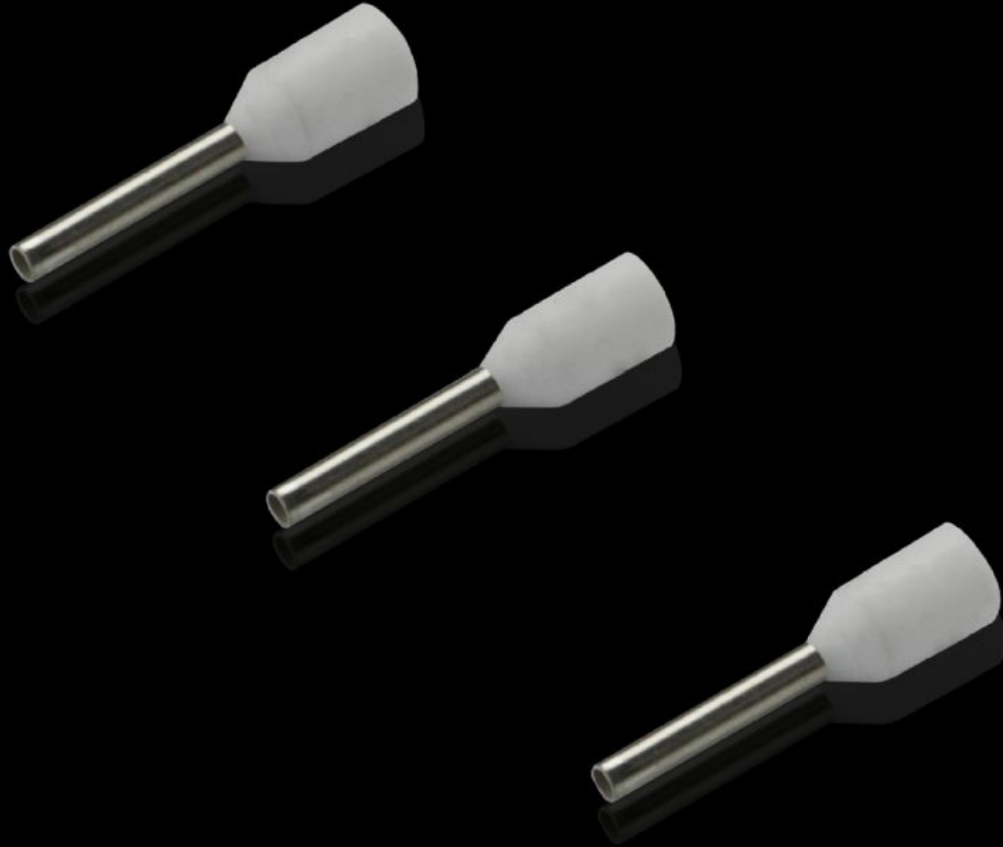


Rittal – The System.

Faster – better – everywhere.

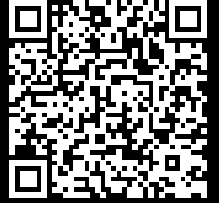

AS 4050.742 Wire end ferrules

State: 07/10/2024 (Source: rittal.com/com-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4050.742 - Wire end ferrules loose

With plastic collar.

Features

Model No.	AS 4050.742
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	White
Length	8 mm
AWG	20
Internal diameter	2.9 mm
For cross-section	0.5 mm ²
DIN colour code	Yes
Multinorm	Yes
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Delivery form	Loose
Packs of	500 pc(s).
Weight/pack	0.001 kg
Net weight	0.5
Gross weight	0.5
Customs tariff number	85369010
EAN	4028177805101
ETIM 8	EC000005

Features

ETIM 7.0	EC000005
ECLASS 8.0	36659290

Approvals

Approvals	UL + C-UL (listed) UR
-----------	--------------------------