


Rittal – The System.

Faster – better – everywhere.

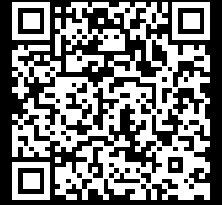

AS 4055.549

Splitter hole punch, round

State: 07/10/2024 (Source: rittal.com/com-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



AS 4055.549 - Splitter hole punch, round for sheet steel, with triple splitting

For punching round cut-outs

Features

Model No.	AS 4055.549
Design	With triple splitting
Product description	
Supply includes	Female dies Male dies
Maximum machinable material thickness, sheet steel	3 mm
Ø punch	49.6 mm
Note	When operating with wrenches, tension screws with ball bearings should be used. Other sizes, see splitter hole punch, round, stainless steel
Suitable for hydraulic bolt order number	4055.663
Tension screw (Ø x L)	19 x 75 mm
Hydraulic tension screw Ø	19 mm
Packs of	1 pc(s).
Weight/pack	0.514 kg
Net weight	0.514
Gross weight	0.556
Customs tariff number	82055980
EAN	4028177808775
ETIM 8	EC000156

Features

ETIM 7.0	EC000156
----------	----------

ECLASS 8.0	21049047
------------	----------