


Rittal – The System.

Faster – better – everywhere.

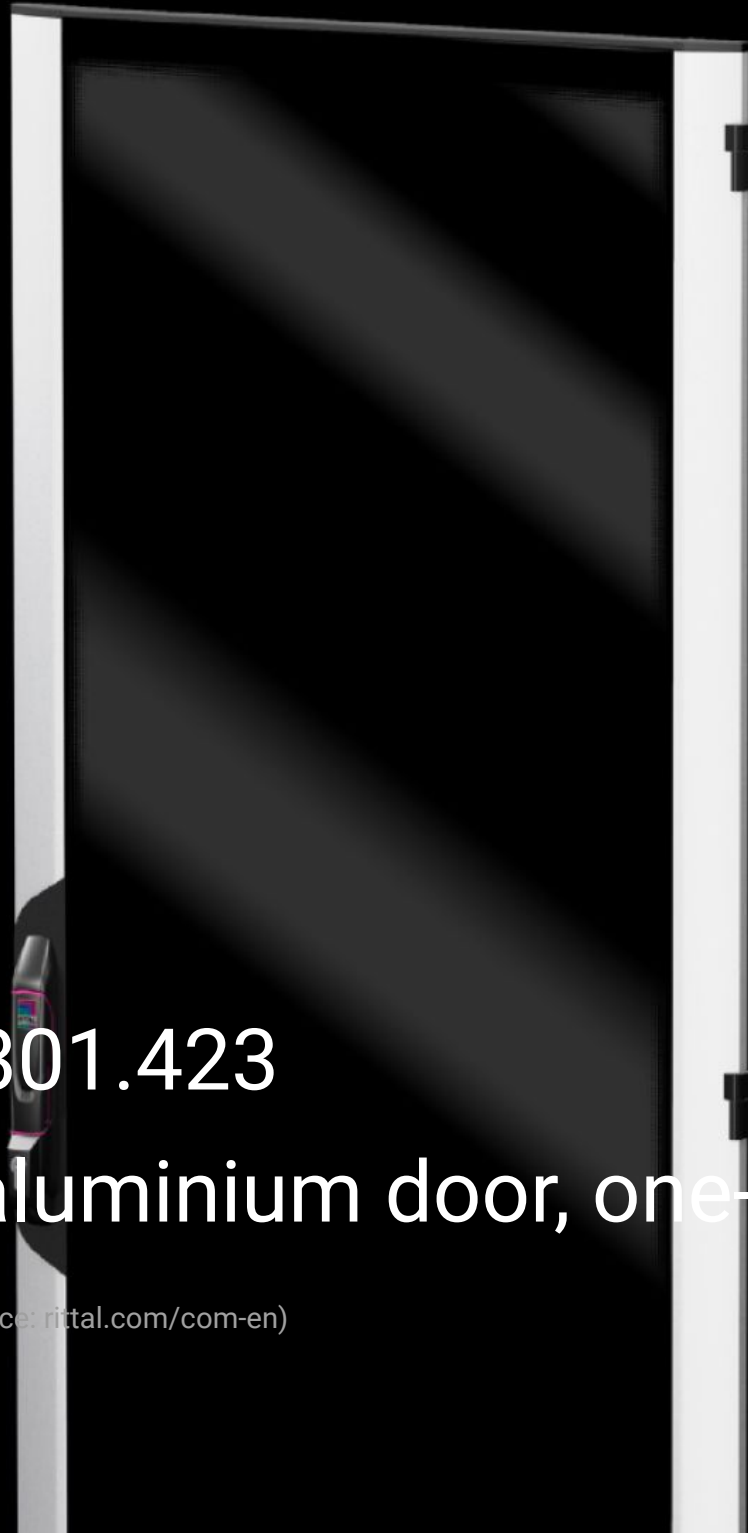

VX_IT 5301.423

Glazed aluminium door, one-piece

State: 19/10/2024 (Source: [rittal.com/com-en](https://www.rittal.com/com-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



VX_IT 5301.423 - Glazed aluminium door, one-piece for VX IT

To replace existing doors.



Features

Model No.	VX IT 5301.423
Product description	To replace existing doors.
Material	Frame: Extruded aluminium section Vertical extrusion: Aluminium, anodised Horizontal extrusion: Aluminium, spray finished Viewing window: Single-pane safety glass, 3 mm
Colour	Comfort handle VX, hinges, horizontal extrusion: RAL 9005 Vertical profile: silver coloured
Supply includes	Door with comfort handle VX for semi-cylinders with security lock 3524 E 3 x 180° hinges, fitted Assembly parts
Assembly instruction	For a door opening angle of 180° when baying, a 180° baying hinge is required
Note	Door opening angle for stand-alone siting: max. 240° Door opening angle when baying: max. 105°

Features

IP protection category to IEC 60529	IP 55
To fit	Enclosure type: VX IT Width: = 800 mm Height: = 2,000 mm
Packs of	1 pc(s).
Weight/pack	17.2 kg
Net weight	16.142
Gross weight	17.2
PCF/PU (cradle-to-gate)	65.5 kg CO2 eq (Cat B)
Note on the PCF class	Category B: PCF value (cradle-to-gate) approximated based on product weight and self-declared
EAN	4028177955028
ETIM 7.0	EC000747
ECLASS 8.0	27182204