


# Rittal – The System.

Faster – better – everywhere.

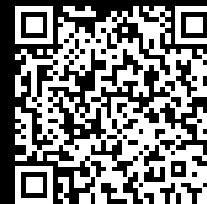

## TP 6707.500 Pedestals

State: 27/09/2024 (Source: [rittal.com/com-en](http://rittal.com/com-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TP 6707.500 - Pedestals

Four widths and two different depths are the basis for every TopConsole solution.

## Features

Model No.	TP 6707.500
Material	Enclosure: Sheet steel 1.5 mm Door and console cover: Sheet steel, 2.0 mm, all-round foamed-in PU seal Mounting plate: Sheet steel, 2.5 mm
Surface finish	Dipcoat-primed, powder-coated on the outside, textured paint Mounting plate: Zinc-plated
Colour	RAL 7035
Supply includes	Enclosure open at top Double door with locking rod, front and rear Mounting plate, depth-adjustable Open base for individual cable entry
Dimensions mounting plate (W x H)	1,499 mm x 571 mm
Number of doors	2
IK Code	IK08
Basic material	Sheet steel
Dimensions	Width: 1,600 mm Height: 675 mm Depth: 500 mm
IP protection category to IEC 60529	IP 55 with selection of the appropriate gland plates
Protection category NEMA	NEMA 12 with selection of the appropriate gland plates or trim panel
Packs of	1 pc(s).
Weight/pack	85 kg
Net weight	80.75

# Features

---

Gross weight	85
Customs tariff number	94032080
EAN	4028177554146
ETIM 7.0	EC000784
ECLASS 8.0	27180504

# Approvals

---

Approvals	UL + C-UL (listed)
-----------	--------------------