
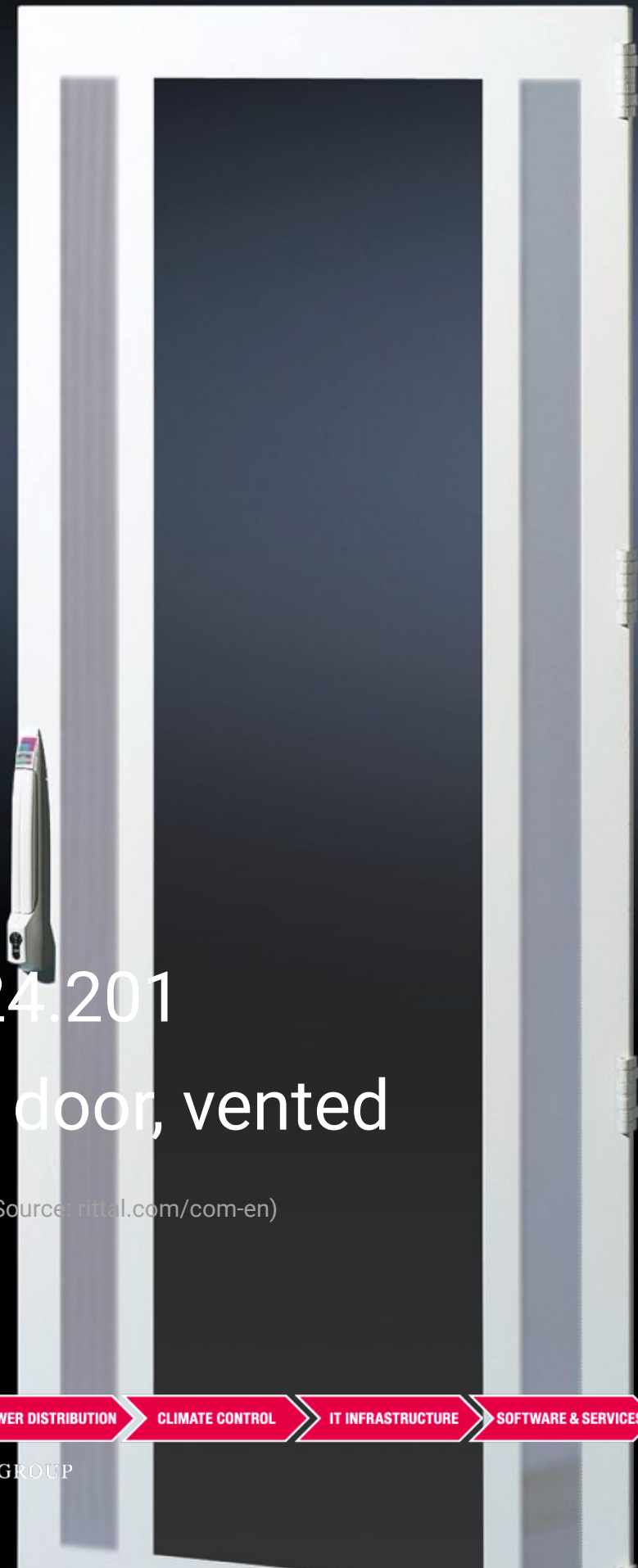


# Rittal – The System.

Faster – better – everywhere.

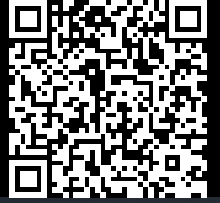

## DK 7824.201 Glazed door, vented

State: 27/09/2024 (Source: [rittal.com/com-en](https://www.rittal.com/com-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7824.201 - Glazed door, vented for TS, TS IT, VX SE

To replace existing doors. With 180° hinges and swivel handle with security lock no. 3524 E.

## Features

|                       |   |
|-----------------------|---|
| Model No.             | DK 7824.201   |
| Product description   | Surface perforated on both sides with air inlet openings > 78% for optimum air throughput.                                      |
| Material              | Door: Sheet steel<br>Viewing window: Single-pane safety glass, 3 mm   |
| Surface finish        | Powder-coated   |
| Colour                | RAL 7035  |
| Supply includes       | Glazed door, vented<br>Comfort handle for profile half-cylinders with security lock 3524 E<br>180° hinges (4)<br>Assembly parts |
| Assembly instruction  | For TS enclosure suites with sheet steel doors, only the 180° hinge 7824.520 may be used.                                       |
| To fit                | Enclosure type: TS<br>TS IT<br>SE<br>Width: 600 mm<br>Height: 2,000 mm  |
| Packs of              | 1 pc(s).  |
| Weight/pack           | 20.4 kg   |
| Net weight            | 19.38   |
| Gross weight          | 20.4  |
| Customs tariff number | 94039910  |
| EAN                   | 4028177236134   |
| ETIM 7.0              | EC000747  |
| ECLASS 8.0            | 27182204  |

# Tender text

Glazed door, vented, for TS

Glazed door, vented, made from 1.5 mm sheet steel with side slotted surfaces in RAL 7035, with foamed-in seal, 180° hinges, 3 mm thick single-pane safety glass, 4-point latch locking rod, comfort handle with security lock no. 3524 E. A semi-cylinder (40/45 mm) to DIN 18254 may be inserted.

Hinges with captive hinge pins, door hinge may be swapped from right to left without dismantling locking rods. Door opening angle 180°.

Material: Sheet steel

Pane: Safety glass, 3 mm

Colour:

Frame: RAL 7035

Pane: Tinted, parsol grey

Dimensions: For enclosures (WxH): W: 600 mm H: 2000 mm