


# Rittal – The System.

Faster – better – everywhere.

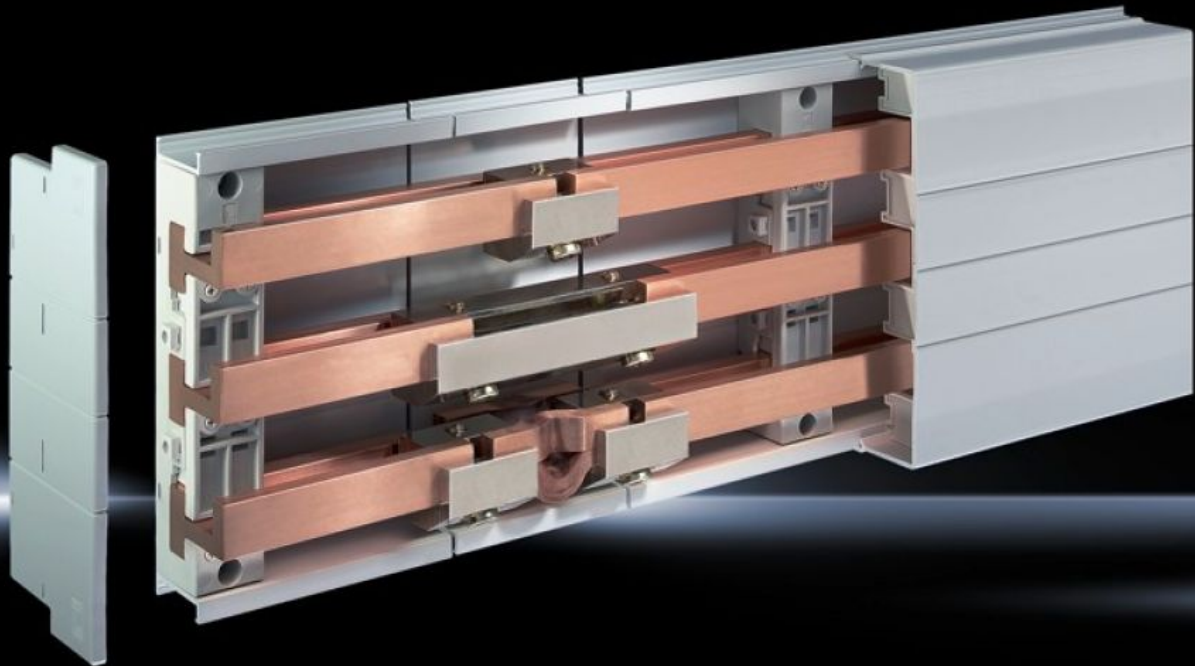

## SV 9342.004 Busbar support PLS

State: 19/10/2024 (Source: [rittal.com/com-en](http://rittal.com/com-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 9342.004 - Busbar support PLS

For PLS special busbars 800 A/1600 A, 3-pole and 4-pole, suitable for top-mounting.

## Features

Model No.	SV 9342.004
Material	Polyamide Fire protection corresponding to UL 94-V0
Colour	RAL 7035
Rated operating voltage	1000 V, 3~
Electrical ratings UL (SCCR)	65 kA - 480 V, support spacing 250 mm, PLS 1600 busbars, circuit breaker max. 1200 A, DIVQ/7
Note on Model No.	The use of a base tray is required for UL applications UL approval only applies in conjunction with AC application
Busbar support design	PLS 1600 PLUS
Number of poles	4-pole
To fit busbars	PLS 1600
Internal attachment	Yes
Centre-to-centre spacing of busbars	60 mm
Packs of	4 pc(s).
Weight/pack	2.276 kg
Net weight	2.2
Gross weight	2.321
Customs tariff number	85469010
EAN	4028177536760
ETIM 7.0	EC001166
ECLASS 8.0	27400607

# Approvals

---

Approvals

ABS  
C-UL  
Lloyds Register of Shipping  
UL + C-UL (listed)

---

Explanations

Declaration of conformity  
Declaration of conformity UK