


Rittal – The System.

Faster – better – everywhere.

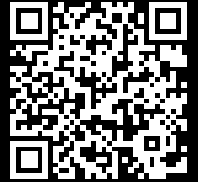

SZ 1581.100 Metal gland plate

State: 19.10.2024. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES



FRIEDHELM LOH GROUP

SZ 1581.100 - Metal gland plate with metric knockouts

Simply knock out the holes for the cable glands using a screwdriver, IP 66 when mounting in the usual position at the bottom.

Features

Model No.	SZ 1581.100
Product description	Simply knock out the holes for the cable glands using a screwdriver.
Material	Sheet steel
Colour	RAL 7035
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
No. of metric knockouts	12 x M20
Dimensions	Width: 221 mm Depth: 90 mm
To fit	Enclosure type: KL
Gland plate	Size: 2
Protection category to IEC 60 529	IP 66 when mounting in the usual position at the bottom
Number knockouts	12
Metric diameter	M20
Packs of	1 pc(s).
Weight/pack	0,24 kg
Net weight	0.23
Gross weight	0.25
Customs tariff number	73269098
EAN	4028177390843
E-Number Sweden	E3404794
ETIM 8	EC000211

Features

ETIM 7.0	EC000211
----------	----------

ECLASS 8.0	27142421
------------	----------