


Rittal – The System.

Faster – better – everywhere.

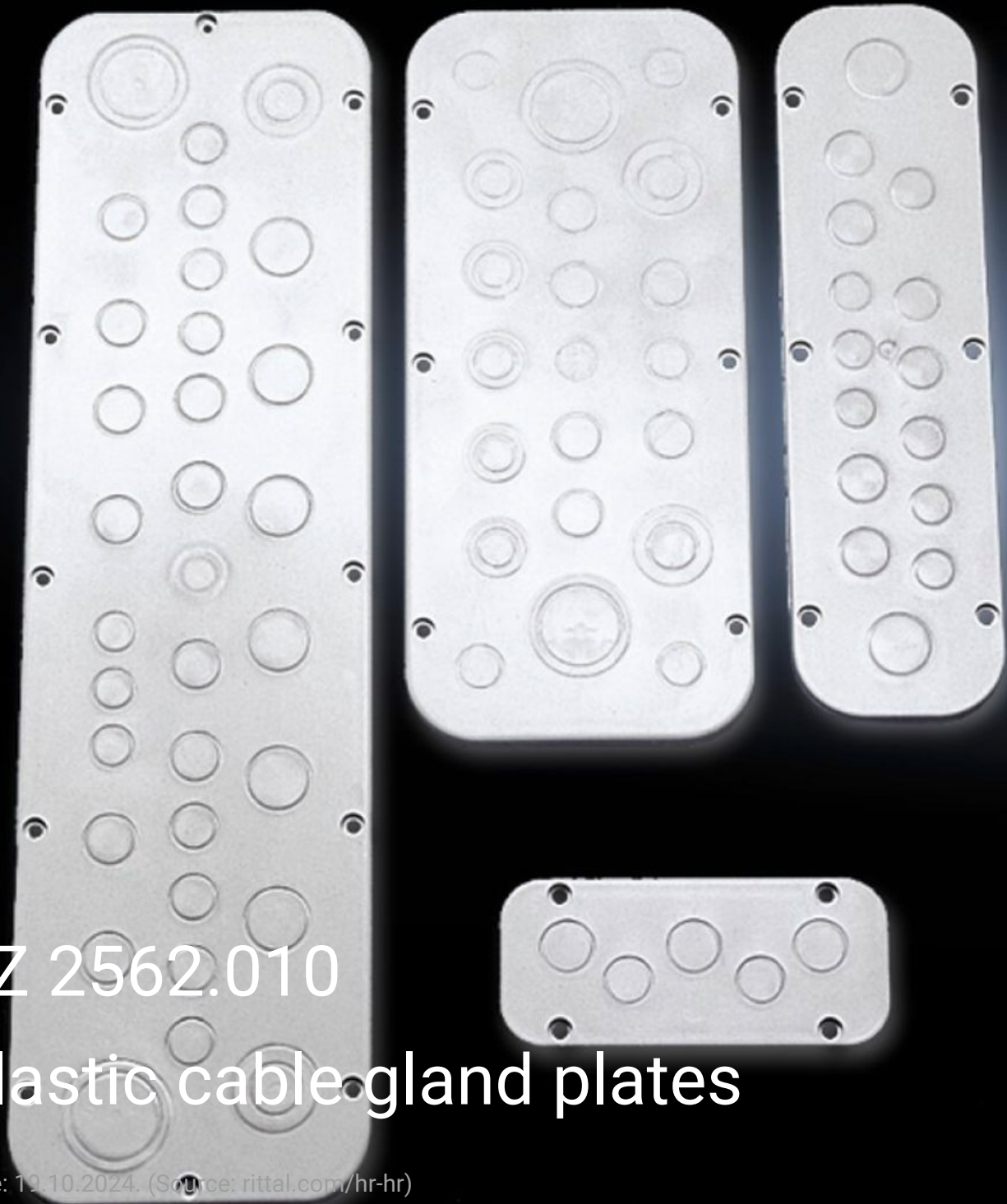

SZ 2562.010

Plastic cable gland plates

State: 19.10.2024. (Source: rittal.com/hr-hr)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 2562.010 - Plastic cable gland plates with metric knockouts

With pre-punched holes for cable glands.

Features

Model No.	SZ 2562.010
Product description	With pre-punched holes for cable glands. Use seal for standard gland plates.
Colour	RAL 7035
Note	The allocation of gland plate sizes is indicated on the relevant enclosures
No. of metric knockouts	2 x M12 4 x M16 4 x M20 10 x M25 4 x M32 4 x M40 2 x M50
Dimensions	Width: 339 mm Depth: 149 mm
To fit	Enclosure type: AE
Gland plate	Size: 4
Operating temperature range	-40 °C...70 °C
Protection category to IEC 60 529	IP 55 if installed correctly
Number knockouts	2 4 4 10 4 4 2

Features

Metric diameter	M12
	M16
	M20
	M25
	M32
	M40
	M50

Packs of	5 pc(s).
----------	----------

Weight/pack	0,995 kg
-------------	----------

Net weight	0.95
------------	------

Gross weight	1
--------------	---

Customs tariff number	39269097
-----------------------	----------

EAN	4028177550278
-----	---------------

E-Number Sweden	E3404763
-----------------	----------

ETIM 8	EC000211
--------	----------

ETIM 7.0	EC000211
----------	----------

ECLASS 8.0	27142421
------------	----------
