


**Rittal – The System.**

Faster – better – everywhere.

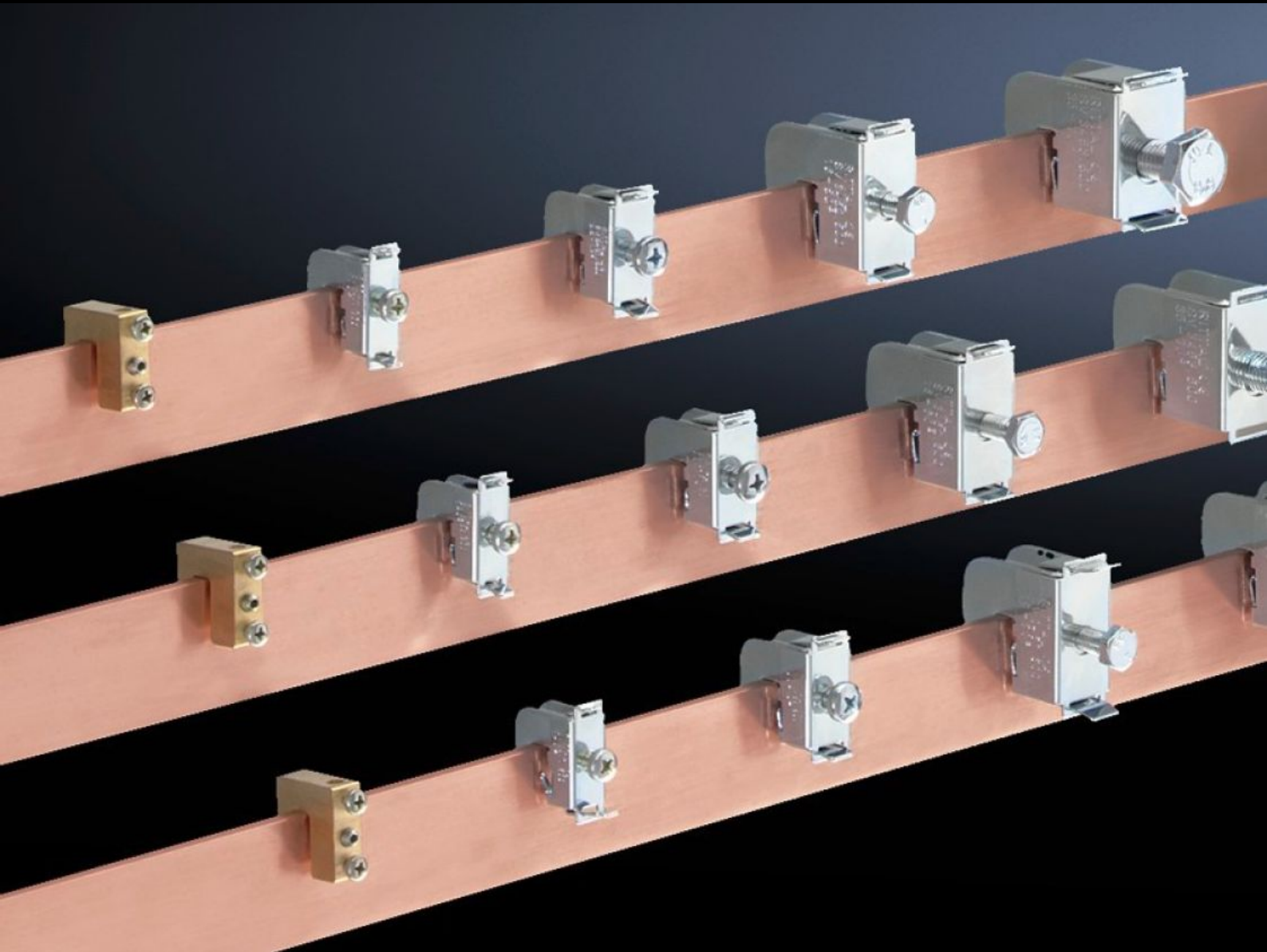

# SV 3550.000 Conductor connection clamp

State: 19.10.2024. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 3550.000 - Conductor connection clamp

For connecting round conductors and laminated copper bars.

## Features

Model No.	SV 3550.000
Product description	For connecting round conductors and laminated copper bars.
Material	Brass
Note	Wire end ferrules should be used with fine wire conductors
Connection for round conductor cross-sections	1 - 4 mm <sup>2</sup>
For bar thickness	3 - 5 mm
Packs of	15 pc(s).
Weight/pack	0,375 kg
Net weight	0.315
Gross weight	0.358
PCF/PU (cradle-to-gate)	1.4 kg CO2 eq (Cat B)
Note on the PCF class	Category B: PCF value (cradle-to-gate) approximated based on product weight and self-declared
Customs tariff number	85369010
EAN	4028177044159
ETIM 8	EC000001
ETIM 7.0	EC000001
ECLASS 8.0	27141146

## Approvals

# Approvals

---

Explanations

Declaration of conformity

Declaration of conformity UK

## Tender text

SV conductor connection clamps  
for E-CU busbars and Rittal PLS.

For bar thickness: 3 - 5 mm

Connection: for round conductors 1 - 4 mm<sup>2</sup>

Wire end ferrules should be used with fine wire  
conductors.

Tightening torque

Conductor connection clamp: 2 Nm

Material: brass