


Rittal – The System.

Faster – better – everywhere.

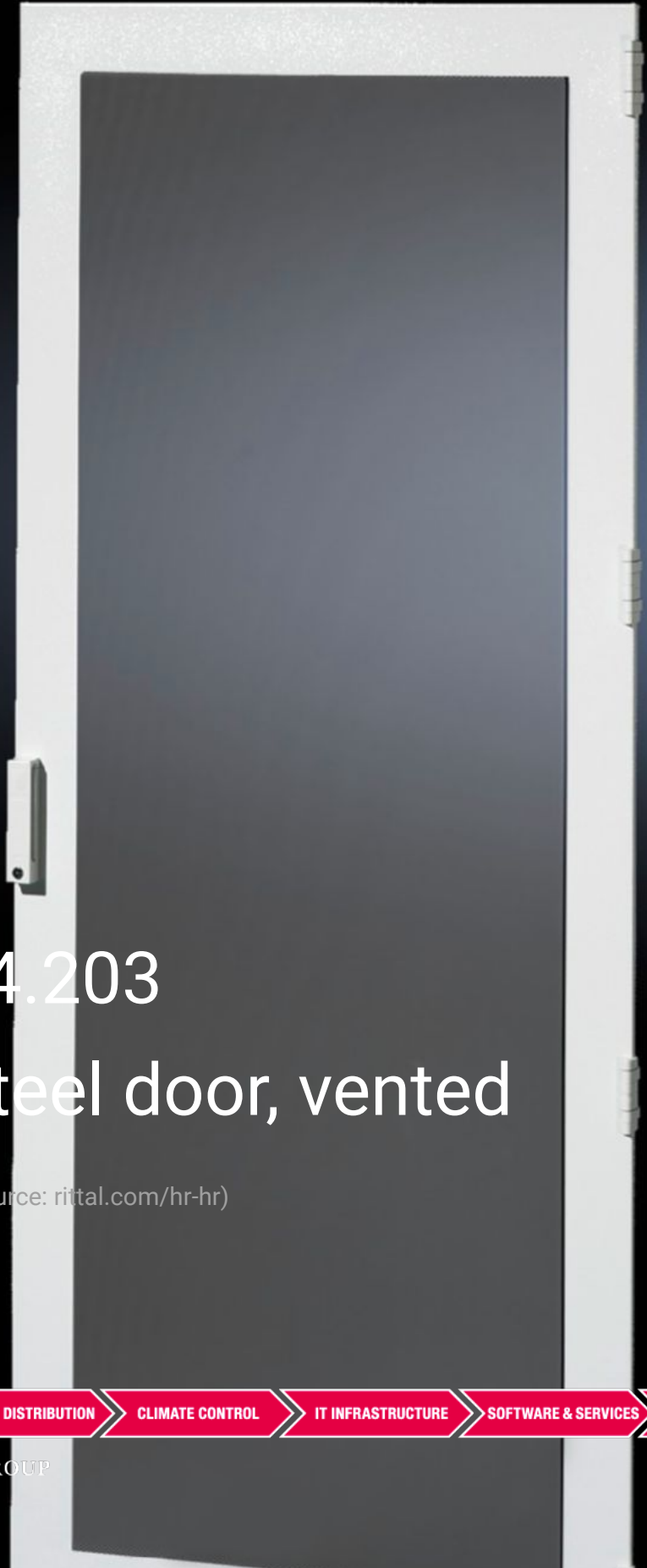

DK 7824.203

Sheet steel door, vented

State: 19.10.2024. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7824.203 - Sheet steel door, vented for DK-TS

To replace existing doors. With 180° hinges and swivel handle with security lock no. 3524 E.

Features

Model No.	DK 7824.203
Product description	With 180° hinges and swivel handle with security lock no. 3524 E, in exchange for comfort handle. For optimum air throughput in network enclosures with a high proportion of active components. Perforated surface with air inlet openings > 78%.
Material	Sheet steel
Colour	RAL 7035
Supply includes	Assembly parts
To fit	Enclosure type: DK-TS Width: 600 mm Height: 2,000 mm
Packs of	1 pc(s).
Weight/pack	20 kg
Net weight	14.3
Gross weight	15.3
Customs tariff number	94039910
EAN	4028177237636
ETIM 7.0	EC000747
ECLASS 8.0	27182204

Tender text

TS vented sheet steel door

Extensively perforated door made from 1.5 mm sheet steel, 180° hinges, locking rod with four locking points, swivel handle with 3524 E security lock, ensures optimum ventilation. A TS 8611.070 comfort handle can be fitted as an option.

The mounting frame integrated inside the door has 25 mm DIN pitch pattern punchings and these enable fan cross members for active maximum configuration ventilation to be fitted as an option.

Material: Sheet steel

Colour: RAL 7035

Dimensions: enclosure (W x H): W: 600 mm H: 2000 mm