


Rittal – The System.

Faster – better – everywhere.

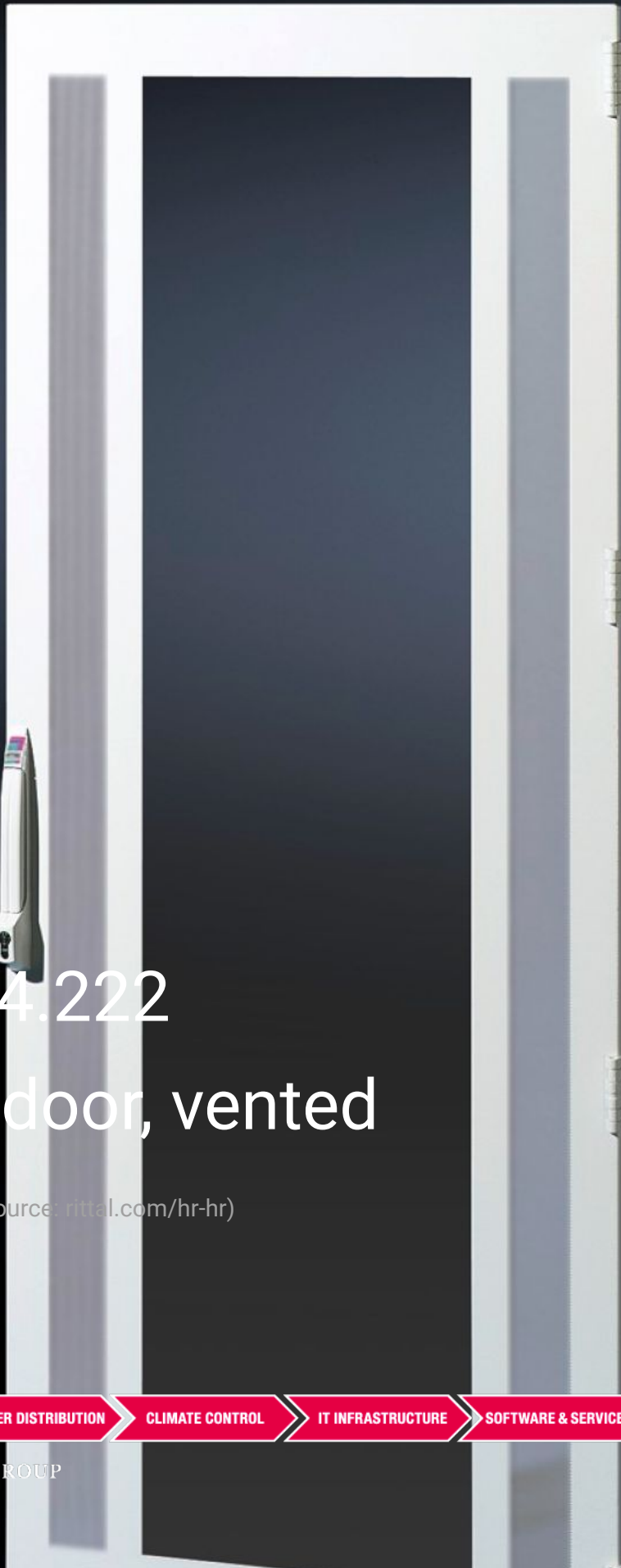

DK 7824.222 Glazed door, vented

State: 26.09.2024. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7824.222 - Glazed door, vented for TS, TS IT, VX SE

To replace existing doors. With 180° hinges and swivel handle with security lock no. 3524 E.

Features

Model No.	DK 7824.222
Product description	Surface perforated on both sides with air inlet openings > 78% for optimum air throughput.
Material	Door: Sheet steel Viewing window: Single-pane safety glass, 3 mm
Surface finish	Powder-coated
Colour	RAL 7035
Supply includes	Glazed door, vented Comfort handle for profile half-cylinders with security lock 3524 E 180° hinges (4) Assembly parts
Assembly instruction	For TS enclosure suites with sheet steel doors, only the 180° hinge 7824.520 may be used.
To fit	Enclosure type: TS TS IT SE Width: 800 mm Height: 2,200 mm
Packs of	1 pc(s).
Weight/pack	43,3 kg
Net weight	22
Gross weight	22.6
Customs tariff number	94039910
EAN	4028177234208
ETIM 7.0	EC000747
ECLASS 8.0	27182204

Tender text

Glazed door, vented, for TS

Glazed door, vented, made from 1.5 mm sheet steel with side slotted surfaces in RAL 7035, with foamed-in seal, 180° hinges, 3 mm thick single-pane safety glass, 4-point latch locking rod, comfort handle with security lock no. 3524 E. A semi-cylinder (40/45 mm) to DIN 18254 may be inserted.

Hinges with captive hinge pins, door hinge may be swapped from right to left without dismantling locking rods. Door opening angle 180°.

Material: Sheet steel

Pane: Safety glass, 3 mm

Colour:

Frame: RAL 7035

Pane: Tinted, parsol grey

Dimensions: For enclosures (WxH): W: 800 mm H: 2200 mm