

Rittal – The System.

Faster – better – everywhere.



SZ 7967.000

Spacer

State: 19.10.2024. (Source: [rittal.com/hr-hr](https://www.rittal.com/hr-hr))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 7967.000 - Spacer for roof plate

To raise the roof for ventilation purposes, in three different heights. Not suitable for crane transportation.

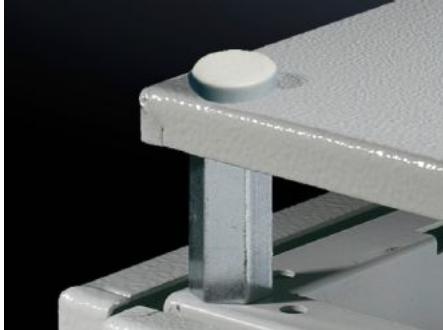

Features

Model No.	SZ 7967.000
Product description	To raise the roof for ventilation purposes, in three different heights.
Material	Hexagon steel section
Surface finish	Zinc-plated
Supply includes	Assembly parts
Assembly instruction	Not suitable for combination with 482.6 mm (19") mounting frame Not suitable for crane transportation
Dimensions	Height: 50 mm
Dimensions	Thread: M12
To fit	Enclosure type: VX TS
Packs of	4 pc(s).
Weight/pack	0,54 kg
Net weight	0.444
Gross weight	0.539
PCF/PU (cradle-to-gate)	2.1 kg CO2 eq (Cat B)
Note on the PCF class	Category B: PCF value (cradle-to-gate) approximated based on product weight and self-declared

Features

Customs tariff number	73181900
EAN	4028177186934
E-Number Sweden	E7239676
ETIM 7.0	EC002625
ECLASS 8.0	27189234

Tender text

Spacers, 50 mm

Material: Hexagonal sectional steel, zinc-plated,
passivated,