


# Rittal – The System.

Faster – better – everywhere.

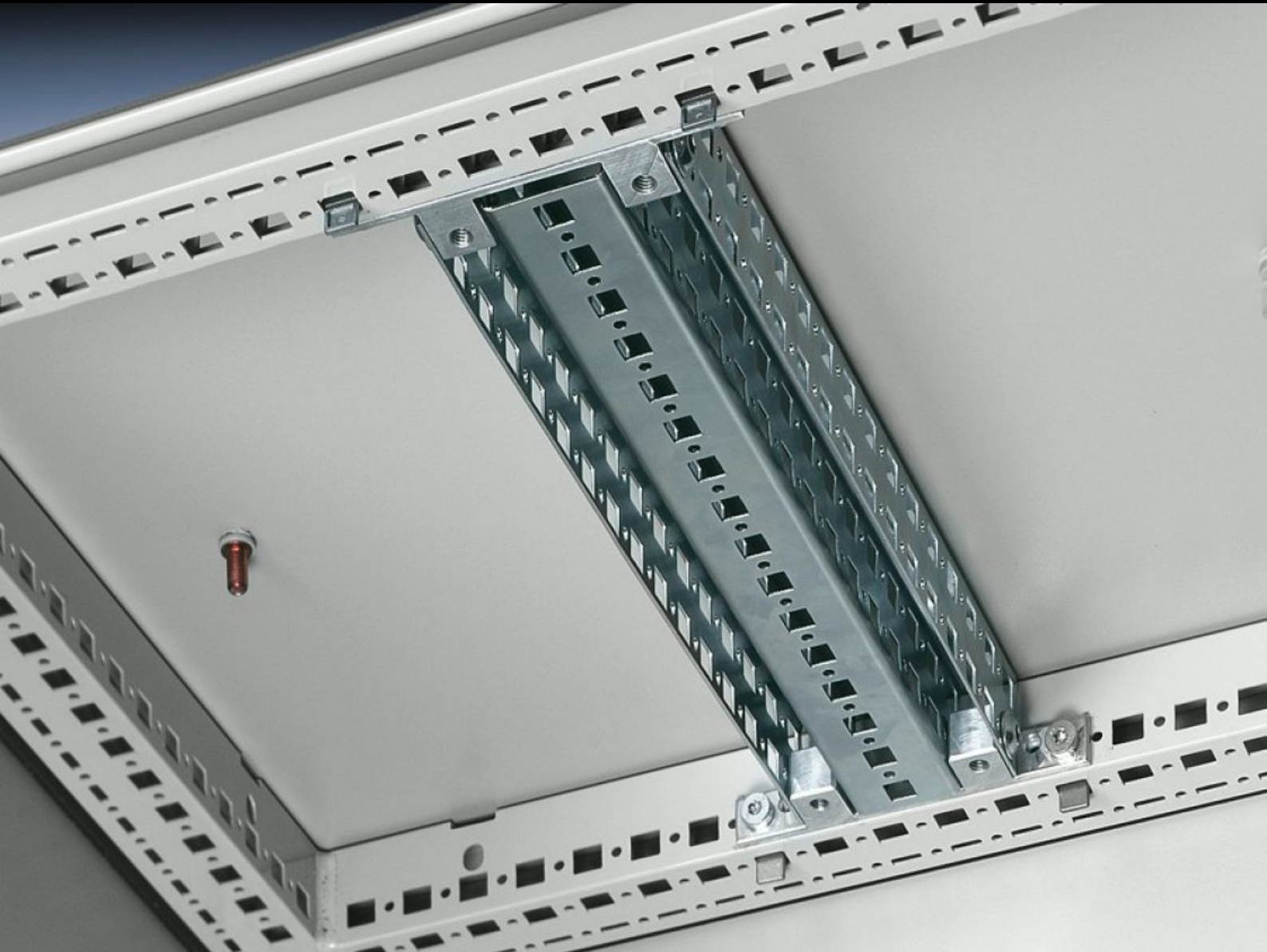

## TS 8612.650

# TS punched sections without mounting flanges, 45 x 88 mm

State: 2024.9.27 (Source: [rittal.com/lt-en](http://rittal.com/lt-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# TS 8612.650 - TS punched sections without mounting flanges, 45 x 88 mm

Heavy top-mounted equipment mounted directly on the internal surfaces (e.g. roof) is supported. Mounted on the side or rear, the enclosure can then be screw-fastened securely to the machine.

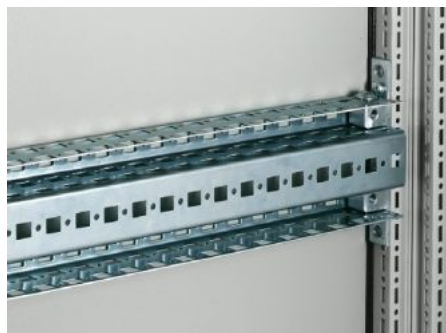

## Features

Model No.	TS 8612.650
Design	for the inner mounting level
Product description	Heavy top-mounted equipment mounted directly on the internal surfaces (e.g. roof) is supported. Mounted on the side or rear, the enclosure can then be screw-fastened securely to the machine. The twin profile with 11 rows of holes offers numerous additional opportunities for interior installation.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
Installation options	On the vertical and horizontal TS, VX SE enclosure section
To fit	Enclosure type: the inner mounting level To fit width/depth: 500 mm
Packs of	2 pc(s).
Weight/pack	2.612 kg
Net weight	2.6
Gross weight	2.611

# Features

---

Customs tariff number	73269098
EAN	4028177267053
ETIM 7.0	EC002625
ECLASS 8.0	27189234

---