


Rittal – The System.

Faster – better – everywhere.

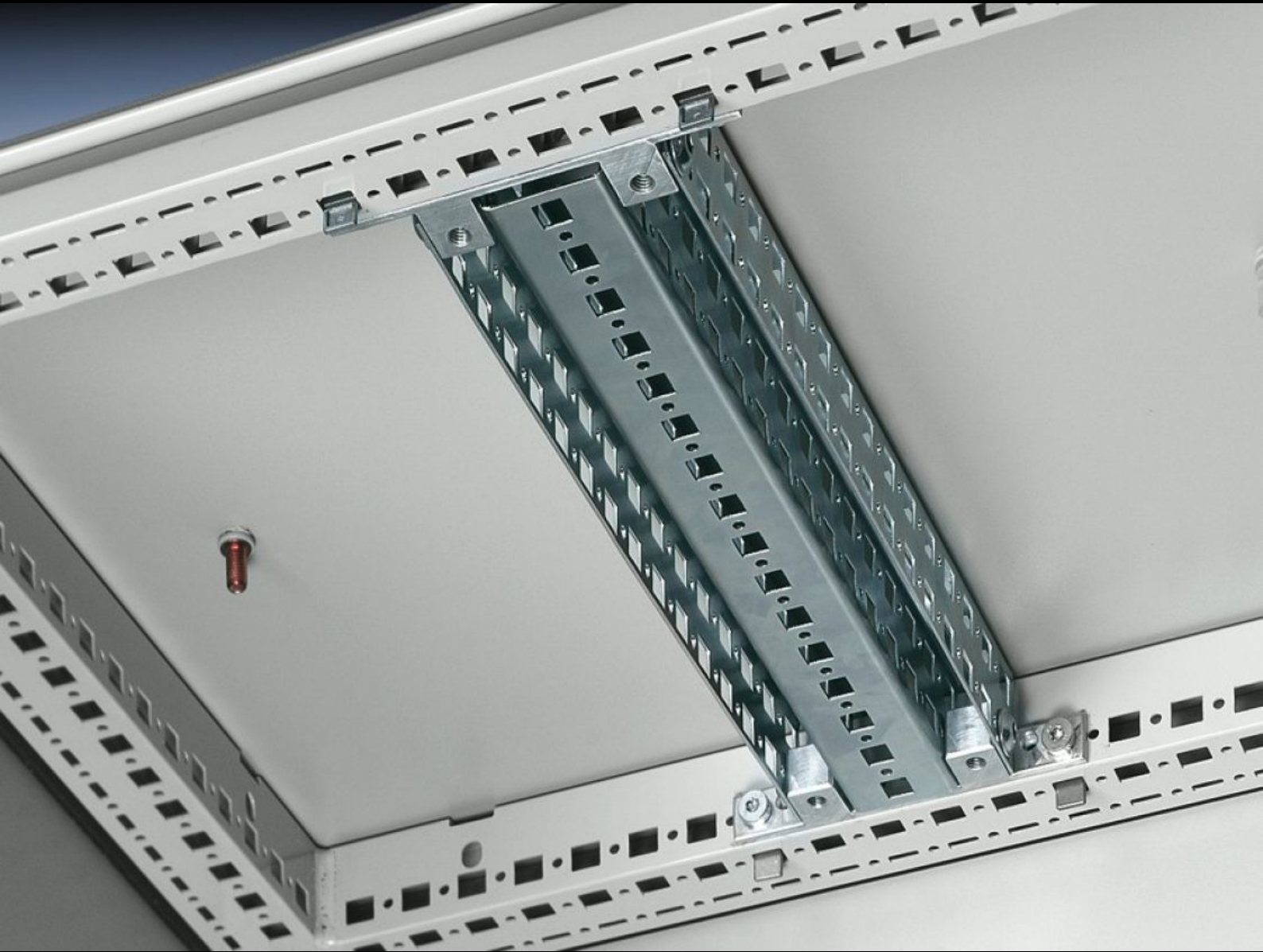

TS 8612.660

TS punched sections without mounting flanges, 45 x 88 mm

State: 2024.10.19 (Source: [rittal.com/lt-en](https://www.rittal.com/lt-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



TS 8612.660 - TS punched sections without mounting flanges, 45 x 88 mm

Heavy top-mounted equipment mounted directly on the internal surfaces (e.g. roof) is supported. Mounted on the side or rear, the enclosure can then be screw-fastened securely to the machine.

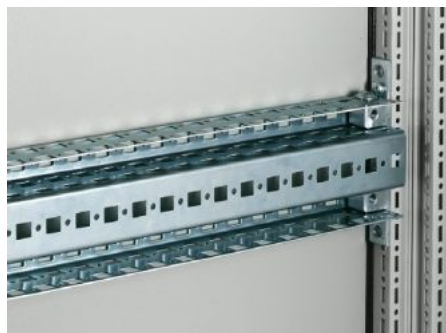

Features

Model No.	TS 8612.660
Design	for the inner mounting level
Product description	Heavy top-mounted equipment mounted directly on the internal surfaces (e.g. roof) is supported. Mounted on the side or rear, the enclosure can then be screw-fastened securely to the machine. The twin profile with 11 rows of holes offers numerous additional opportunities for interior installation.
Material	Sheet steel
Surface finish	Zinc-plated
Supply includes	Assembly parts
Installation options	On the vertical and horizontal TS, VX SE enclosure section
To fit	Enclosure type: the inner mounting level To fit width/depth: 600 mm
Packs of	2 pc(s).
Weight/pack	3 kg
Net weight	2.8
Gross weight	3.02

Features

Customs tariff number	73269098
EAN	4028177267060
ETIM 7.0	EC002625
ECLASS 8.0	27189234
