


**Rittal – The System.**

Faster – better – everywhere.

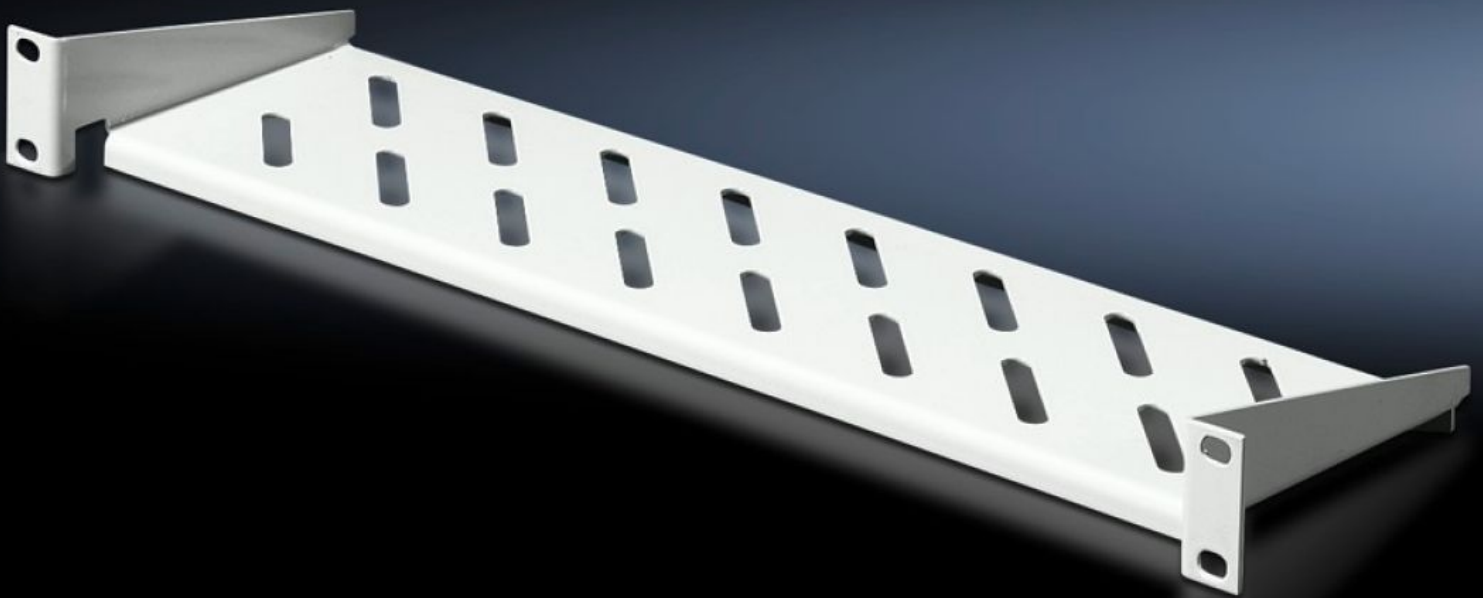

**DK 7119.140**

**Component shelf 1 U, static  
installation**

State: 27/09/2024 (Source: [rittal.com/nz-en](http://rittal.com/nz-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# DK 7119.140 - Component shelf 1 U, static installation 482.6 mm (19") system punchings

482.6 mm (19")/535 mm (metric), support surface for small active components such as modems or mini-hubs in 482.6 mm (19") or metric levels, load capacity: 10 kg.

## Features

Model No.	DK 7119.140
Design	482.6 mm (19") version
Product description	The ideal support surface for small active components such as modems or mini-hubs.
Material	Sheet steel
Colour	RAL 7035
Load capacity	10 kg surface load, static
Note	Not suitable for combination with telescopic slides. Free installation height inside the U approx. 35 mm
Dimensions	Width: 482.6 mm Depth: 140 mm
Packs of	1 pc(s).
Weight/pack	0.835 kg
Net weight	0.781
Gross weight	0.881
PCF/PU (Cradle-to-Gate)	3.2 kg CO2 eq (Cat B)
Note on the PCF class	Category B: PCF value (cradle-to-gate) approximated based on product weight and self-declared
Customs tariff number	94039910
EAN	4028177221444
ETIM 7.0	EC002620
ECLASS 8.0	27189261

## Tender text

482.6 mm (19 inch) single-level component shelf,  
D: 140 mm

Load capacity: 10 kg surface load, static

Material: Sheet steel, spray finished in RAL 7035