

# Rittal – The System.

Faster – better – everywhere.



## SZ 2422.000

# Spacer

State: 19.10.2024 (Source: [rittal.com/si-sl](http://rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 2422.000 - Spacer for roof plate

To raise the roof for ventilation purposes, in three different heights. Not suitable for crane transportation.

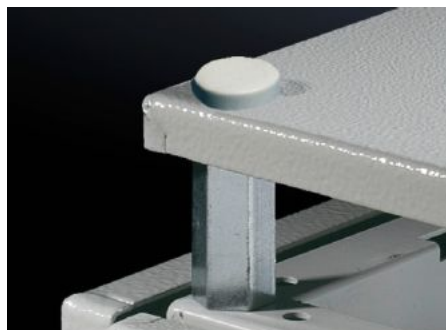

## Features

Model No.	SZ 2422.000
Product description	To raise the roof for ventilation purposes, in three different heights.
Material	Hexagon steel section
Surface finish	Zinc-plated
Supply includes	Assembly parts
Assembly instruction	Not suitable for crane transportation
Dimensions	Height: 10 mm
Dimensions	Thread: M12
To fit	Enclosure type: VX TS
Packs of	4 pc(s).
Weight/pack	0,16 kg
Net weight	0.12
Gross weight	0.161
PCF/PU (Cradle-to-Gate)	0.6 kg CO2 eq (Cat B)
Note on the PCF class	Category B: PCF value (cradle-to-gate) approximated based on product weight and self-declared

# Features

---

Customs tariff number	83024900
EAN	4028177022775
E-Number Sweden	E7239751
ETIM 8	EC002625
ETIM 7.0	EC002625
ECLASS 8.0	27189234

---