


Rittal – The System.

Faster – better – everywhere.

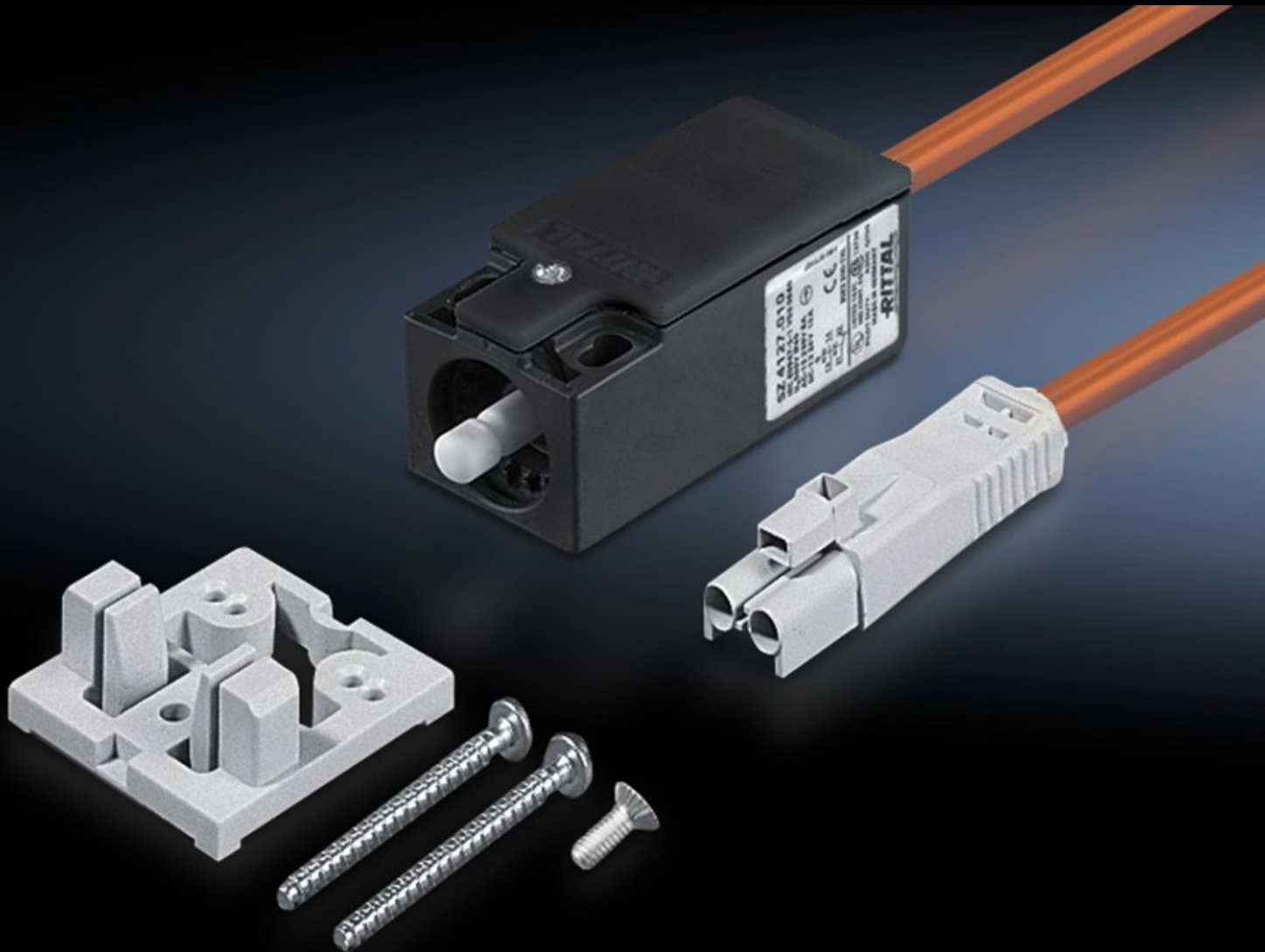

SZ 4315.520 Door-operated switch

State: 27.9.2024 (Source: [rittal.com/si-sl](https://www.rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 4315.520 - Door-operated switch

with mounting accessories, with or without connection cable.

Features

Model No.	SZ 4315.520
Design	With connection cable
Length	600 mm
Rated impulse withstand voltage, phase to phase	6000 V AC
Rated insulation voltage	400 V AC
Installation options	for standard and courtesy light without integral door-operated switch
Dimensions	Length: 600 mm
Electrical connection	240 V AC/6 A 125 V AC/8 A 24 V AC/6 A 24 V DC/6 A
Rated operating voltage	400 V
IP protection category to IEC 60529	IP 40
Packs of	1 pc(s).
Weight/pack	0,12 kg
Net weight	0.119
Gross weight	0.124
Customs tariff number	85365080
EAN	4028177581357
ETIM 8	EC002626
ETIM 7.0	EC002626

Features

ECLASS 8.0

27189266

Approvals

Approvals

CQC-CCC

Explanations

Declaration of conformity

Declaration of conformity UK