


Rittal – The System.

Faster – better – everywhere.

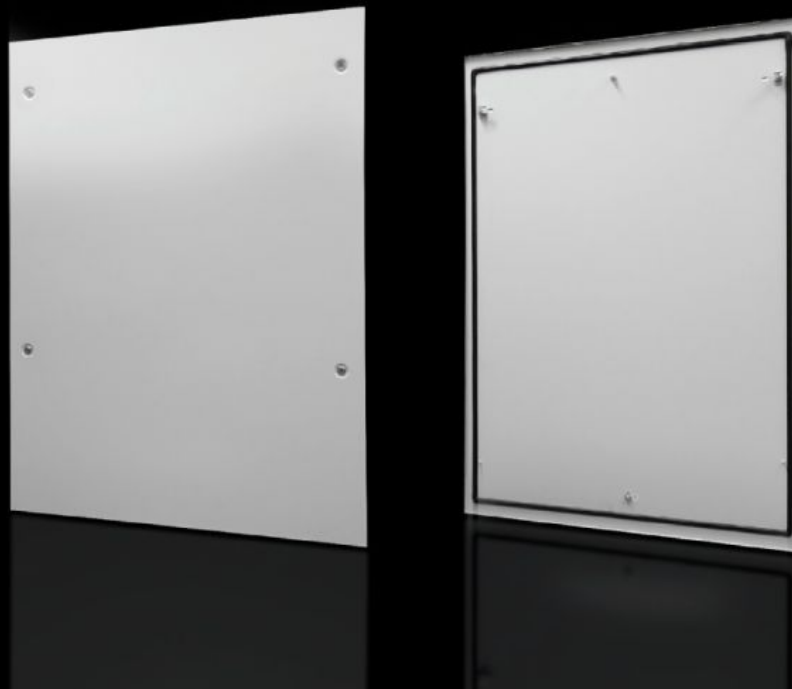

DK 7824.128 Side panel, lockable

State: 19.10.2024 (Source: [rittal.com/si-sl](https://www.rittal.com/si-sl))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



DK 7824.128 - Side panel, lockable for TS, TS IT

Side panel, lockable, sheet steel, for TS.



Features

Model No.	DK 7824.128
Product description	Simply locate from above. Lock with security lock no. 3524 E. Earthing bolt with contact track.
Material	Sheet steel
Surface finish	Spray-finished
Colour	RAL 7035
Supply includes	2 side panels each with 4 security locks no. 3524 E
To fit	Enclosure type: TS IT TX CableNet TS Height: 1,200 mm Depth: 800 mm
Basic material	Sheet steel
Packs of	2 pc(s).
Weight/pack	38 kg
Net weight	24
Gross weight	25.8
Customs tariff number	94039910
EAN	4028177232235

Features

E-Number Sweden	E7239564
ETIM 7.0	EC002524
ECLASS 8.0	27182101

Tender text

Side panel, plug-type, for TS
H x D = 1200 x 800 mm, RAL 7035

Side panel fitted with a T-lock.
Material: Sheet steel, spray finished in RAL 7035
For 1200 mm x 800 mm enclosures