


# Rittal – The System.

Faster – better – everywhere.

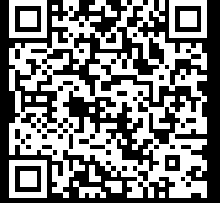

## SV 3057.000 Busbar support

State: 27/09/2024 (Source: [rittal.com/uae-en](http://rittal.com/uae-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SV 3057.000 - Busbar support

For busbar systems 1250 A (100 mm), 1600 A (185 mm), 2500 A (150 mm), 3000 A (150 mm).

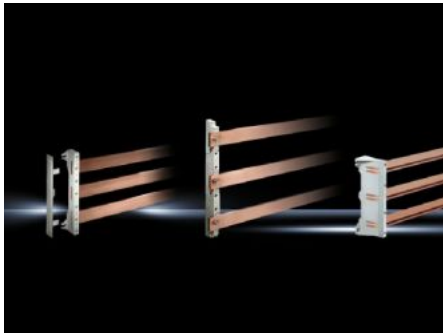

## Features

Model No.	SV 3057.000
Material	Fibreglass-reinforced, thermoplastic polyester (PBT) Fire protection corresponding to UL 94-V0
Colour	RAL 7035
Number of poles	3-pole 150 mm
To fit busbars	60 x 10 80 x 10 100 x 10
Rated current max.	3,000 A
Dimensions	Width: 30 mm Height: 420 mm Depth: 170 mm
Packs of	2 pc(s).
Weight/pack	4.696 kg
Net weight	4.496
Gross weight	4.695
Customs tariff number	85469010
EAN	4028177035812
ETIM 8	EC001166

# Features

---

ETIM 7.0	EC001166
ECLASS 8.0	27400607

---

# Approvals

---

Explanations	Declaration of conformity Declaration of conformity UK
--------------	---

# Tender text

SV busbar support  
for accommodating busbars. Suitable for busbars  
3 x 2 x 100 x 10 mm.

Rated operating voltage: 1000 V~, 50/60 Hz  
to VDE 0660

Rated current: up to 3000 A

Material: PBT

Fire protection: UL 94-V0

Continuous operating temperature: 140 °C

Bar centre distance: 150 mm

Tightening torques

Assembly screws: 8 - 10 Nm

Lid attachment: 5 - 10 Nm