


**Rittal – The System.**

Faster – better – everywhere.

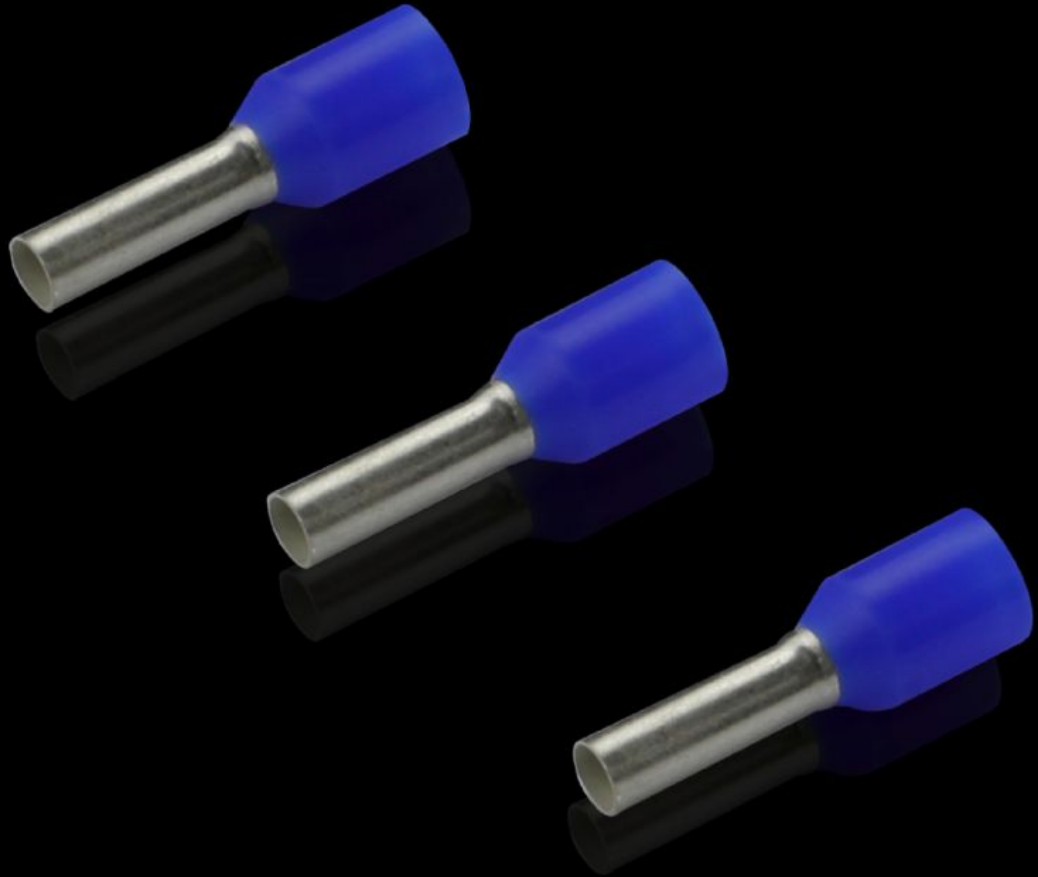

# AS 4050.734

## Wire end ferrules

State: 19/10/2024 (Source: [rittal.com/uae-en](http://rittal.com/uae-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# AS 4050.734 - Wire end ferrules loose

With plastic collar.

## Features

Model No.	AS 4050.734
Product description	With plastic collar.
Technical specifications	Heat-resistant to 105 °C
Material	E-Cu, galvanic tin-plated Plastic collar: Polypropylene
Colour	Blue
Length	8 mm
AWG	14
Internal diameter	4.2 mm
For cross-section	2.5 mm <sup>2</sup>
DIN colour code	Yes
Note	UL-certified in conjunction with the relevant tools, such as crimping machines. For bespoke advice, please contact your Rittal sales consultant.
Standards	AEH DIN 46228
To fit Model No.	4051.205 4051.210 4050.452
Delivery form	Loose
Packs of	500 pc(s).
Weight/pack	0.5 kg
Gross weight	0.073
Customs tariff number	85369010
EAN	4028177805026

# Features

---

ETIM 8	EC000005
ETIM 7.0	EC000005
ECLASS 8.0	36659290

# Approvals

---

Approvals	UL + C-UL (listed) UR
-----------	--------------------------