


Rittal – The System.

Faster – better – everywhere.

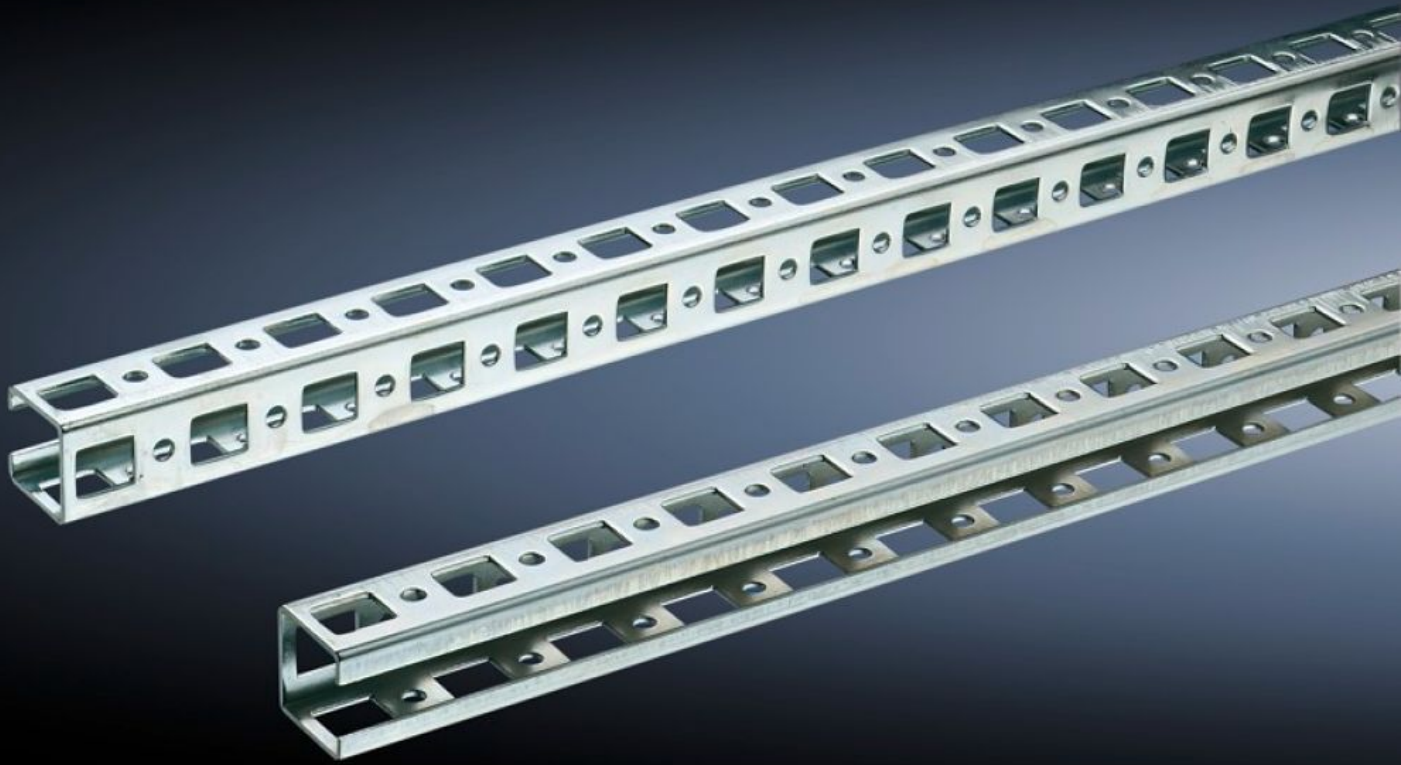

SZ 4169.000

Punched rail 23 x 23 mm

State: 19/10/2024 (Source: rittal.com/uae-en)

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



SZ 4169.000 - Punched rail 23 x 23 mm for VX, TS, VX SE

For mounting on the horizontal and vertical enclosure sections via additional assembly components.



Features

Model No.	SZ 4169.000
Material	Sheet steel
Surface finish	Zinc-plated
Length	295 mm
Installation options	<p>In VX on the vertical and horizontal enclosure section using mounting brackets TS</p> <p>In the VX SE, on the vertical enclosure section via mounting brackets in conjunction with the VX adaptor rail</p> <p>In VX SE, on the horizontal extrusion/in the roof via mounting brackets in conjunction with the VX adaptor rail in the depth.</p> <p>On the vertical enclosure section: Directly via support brackets TS, via adaptor rail for PS compatibility in conjunction with angle brackets, mounting brackets or support brackets PS</p> <p>On the horizontal enclosure section: Directly via angle brackets, mounting brackets or support brackets PS</p>
To fit	<p>Enclosure type: VX</p> <p>TS</p> <p>VX SE</p> <p>Suitable for width or height or depth: 400 mm</p>
Packs of	12 pc(s).
Weight/pack	2.256 kg

Features

Net weight	2.052
Gross weight	2.22
PCF/PU (cradle-to-gate)	8.6 kg CO2 eq (Cat B)
Note on the PCF class	Category B: PCF value (cradle-to-gate) approximated based on product weight and self-declared
Customs tariff number	73269098
EAN	4028177093102
ETIM 8	EC002620
ETIM 7.0	EC002625
ECLASS 8.0	27189234