


# Rittal – The System.

Faster – better – everywhere.

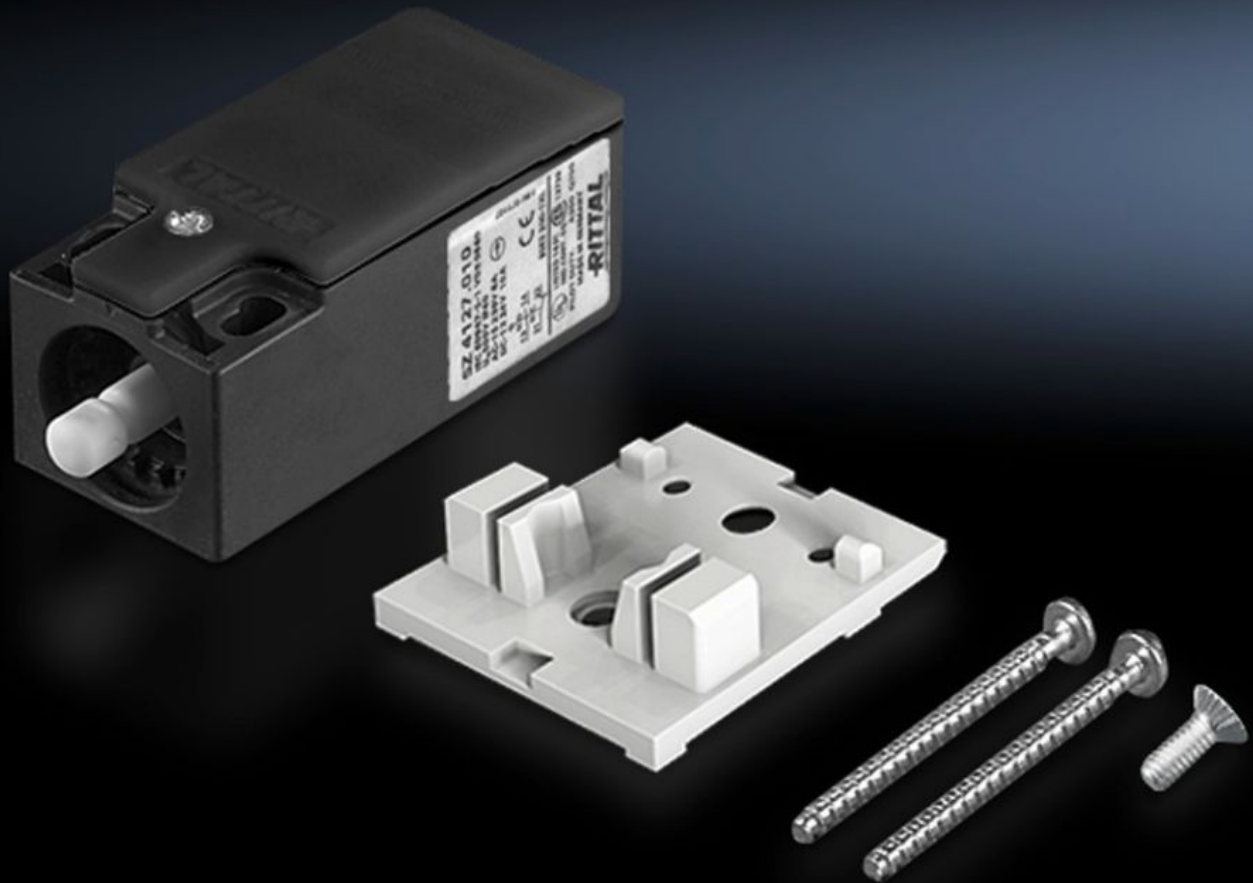

## SZ 4127.010 Door-Operated Switch

State: 11/22/2024 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SZ 4127.010 - Door-Operated Switch

With mounting accessories, with or without connection cable.

## Features

Model No.	SZ 4127.010
Version	without connection cable
Note	For installation in VX IT only in conjunction with VX mounting bracket for door-operated switch.
Rated impulse withstand voltage, phase to phase	6000 V AC
Rated insulation voltage	400 V AC
Installation options	for LED System Light for standard and courtesy lights without an integrated door-operated switch For cooling units and air-water heat exchangers
Electrical connection	240 V AC/6 A 125 V DC/8 A 24 V AC/6 A 24 V DC/6 A
Rated operating voltage	400 V
Protection category IP to IEC 60529	IP 40
Packaging unit	1 pc(s).
Weight/packaging unit	0.075 kg 0.2 lb.
Net weight	0.068
Gross weight	0.076
Customs tariff number	85365080
EAN	4028177497740
E-Number Sweden	E3404494

# Features

---

ETIM 8	EC002626
ETIM 7.0	EC002626
ECLASS 8.0	27189266

---

# Approvals

---

Approvals	CQC-CCC CSA UL + C-UL (listed)
Explanations	Declaration of conformity Declaration of conformity UK

---