


**Rittal – The System.**

Faster – better – everywhere.

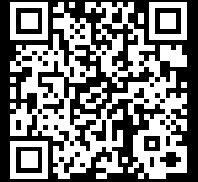

# SK 7990.000

## Fan expansion kit

State: 9/20/2024 (Source: [rittal.com/us-en](http://rittal.com/us-en))

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE

SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



# SK 7990.000 - Fan expansion kit for VX IT, TS IT

Fan expansion kit with integrated speed control for retrofitting in fan modules 5503.010, 5503.020 and 5503.025.



## Features

Model No.	SK 7990.000
Version	Without roof plate
Product description	Fan expansion kit with integrated speed control for installation in fan modules 5503.xxx.
Benefits	Complete, ready-to-connect solution Energy-efficient speed control with preset characteristic curve International approvals and multi-voltage capability for worldwide use
Material	Plastic
Color	RAL 9005
Supply includes	Fans Protection grille Assembly components Installation and Short User's Guide
Air performance (at operating point)	150 m <sup>3</sup> /h
Rated operating voltage	24 V (DC)
Rated current max.	At 50 Hz: 0.32 A At 60 Hz: 0.32 A

# Features

---

Dimensions	Width: 119 mm Height: 25 mm Depth: 119 mm Width: 4.69 " Height: 0.98 " Depth: 4.69 "
Protection category IP to IEC 60529	IP 20
Speed	100 %
Note	Reduction of the specified air flow to 150 m <sup>3</sup> /h at 25 Pa counter-pressure
Sound pressure level (at operating point)	44 dB(A)
Operating temperature range	5 °C...55 °C 41 °F...131 °F
Rated power	7.7 W
Weight/packaging unit	0.3 kg 0.7 lb.
Packaging unit	1 pc(s).
Net weight	0.3
Gross weight	0.308
Customs tariff number	84149000
EAN	4028177966345
ETIM 7.0	EC000320
ECLASS 8.0	27180716